

USB 2.0 Sockets Type A

PCB, angled, Multiport 2



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 1.5 A
Voltage rating: 50 V
Insulation resistance: 1000 M Ω min.
Contact resistance: 30 m Ω max.
Dielectric voltage: 750 V AC
Operation temperature: -55 °C to +85 °C

MECHANICAL:

Mating force: \leq 35 N
Unmating force: \geq 10 N

MATERIAL:

Insulator: PBT white UL94V-0
Shell: Brass
Contacts: Phosphorbronze

FINISH:





Shell: Tin plated
Contacts: Gold Flash in contact area
Tin plated on solder tails

HANDLING:

Processing: Wave soldering
Packing: Tray

TOLERANCE:

.X \pm 0.25
.XX \pm 0.20

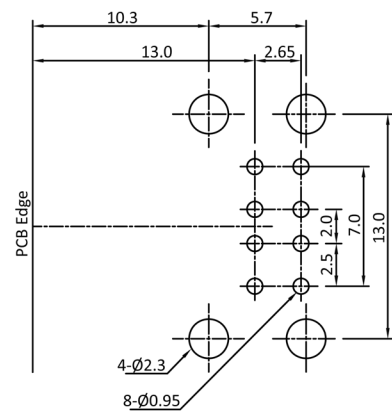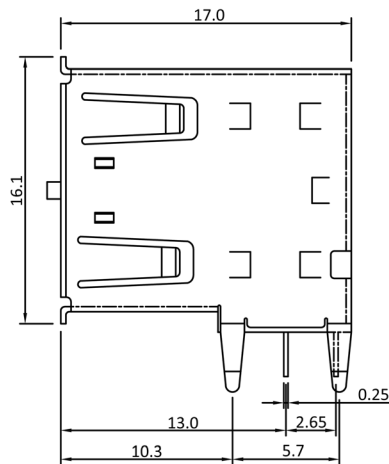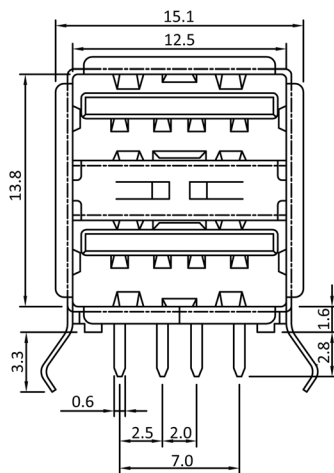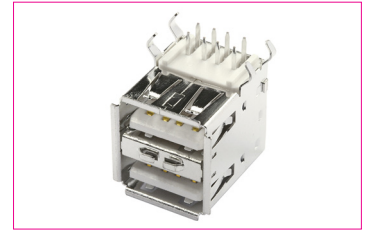

PCB Layout
(Bottom View)

Order-Information

Identifier:

USBBU2A

Socket 2 x Type A angled