

Flat Cable Connector System DIN 41651 Box Header without Locking

Pitch 2.0 mm, straight



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 2 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: Nylon 6T UL94V-0
 Pins: Copper alloy

FINISH:



 


Contacts: Gold Flash

HANDLING:

Processing: Wave soldering

TOLERANCE:

.X ± 0.25
 .XX ± 0.20

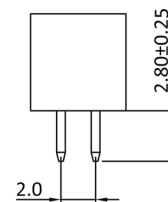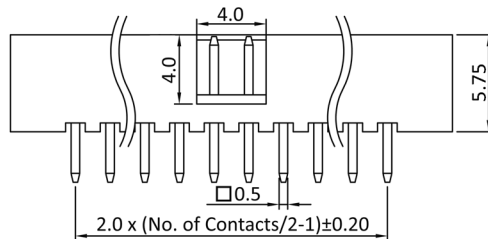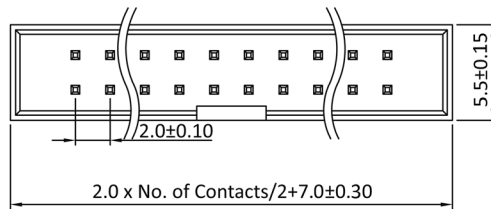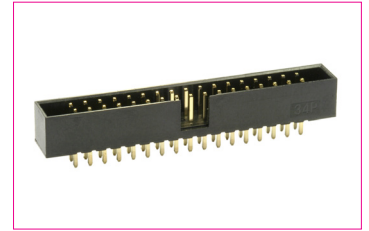

Order-Information

Identifier:	No. of contacts:	Version:	Pitch:	Special:	Packing:
WS	#	G	RM2	#	#
Box Header straight	6: 2 x 3 8: 2 x 4 10: 2 x 5 12: 2 x 6 14: 2 x 7 16: 2 x 8 20: 2 x 10 24: 2 x 12 26: 2 x 13 30: 2 x 15 34: 2 x 17 40: 2 x 20 44: 2 x 22 50: 2 x 25	G: Straight	RM2: Pitch 2.0 mm	empty: w/o Cap * C: with Cap	empty: Tray * T: Tube R: T&R

* = standard