

SPECIFICATION:

Current rating: 1 A
 Voltage rating: 30 V
 Insulation resistance: 500 MΩ min.
 Contact resistance: 30 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -25 °C to +80 °C

MECHANICAL:

Mating force: ≤ 35 N
 Unmating force: ≥ 7 N

MATERIAL:

Insulator: Thermoplastic black UL94V-0
 Shell: Brass
 Contacts: Phosphorbronze

FINISH:







Shell: Nickel plated
 Contacts: Gold Flash in contact area
 Tin plated on solder tails

HANDLING:

Processing: Wave soldering
 Packing: Tray

TOLERANCE:

.X ± 0.30
 .XX ± 0.25

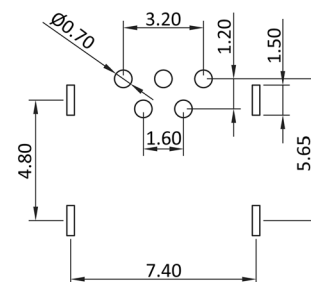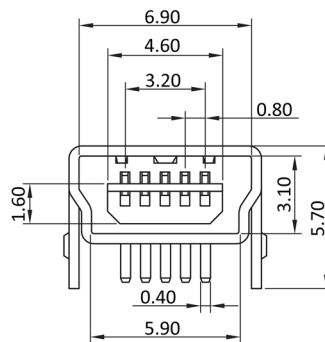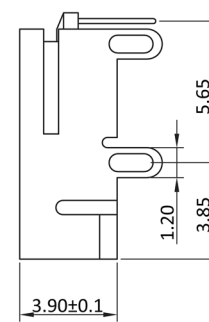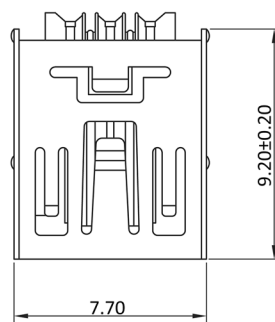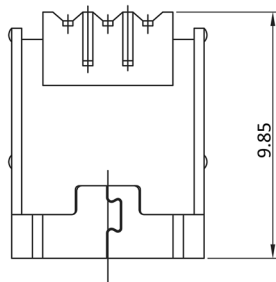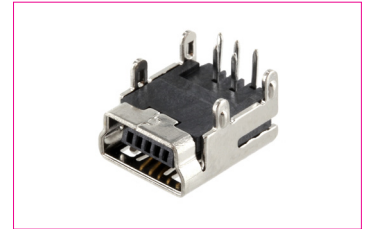

Order-Information

Identifier:

MUB1B5W

Socket 5 pin angled