


# Datasheet

Item no. 1313909/ 1313911

V1\_0717\_01\_en

USB 3.0 Panel Jack, Ø22mm  
 Front: Female Type A  
 Back: Female Type A with 60 cm

Item no.: 1313909- Silver  
 1313911- Black

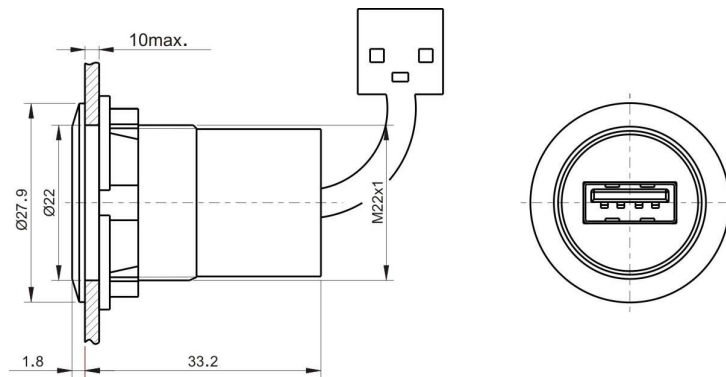

Specification .....	Front: Female Type A Back: Female Type A with 60 cm
Operating Temperature.....	-25°C ~ +55°C (NO-Freezing)
Operating Humidity.....	45~85%RH(NO Condensation)
Panel Thickness.....	1~10 mm
Body Material.....	Aluminium anodized (Silver color)
Transmission Rate .....	≥30MB/s

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).  
 All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.