


**Φ25 mm, 2x USB3.0 FEMALE A - MALE A with 60cm**      **Version 10/15**  
**cable,**  
**BN no. 1313910 (silver surface)**  
**1313912(black surface)**

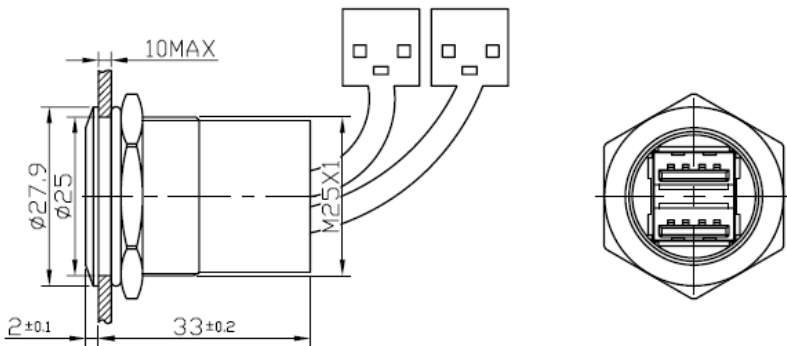

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification .....	2x USB3.0 FEMALE A –MALE A with 60cm cable
Mounting diameter .....	25 mm
Body material .....	aluminium anodized(silver colour)
Operating and storage temperature .....	-20 to +55 °C
Operating and storage humidity .....	45 to 85 % RH
Panel thickness .....	1 ~ 10 mm
Transmission speed .....	≥ 100MB/s