



CLIFF

3.5mm VERTICAL JACK SOCKET

Stereo switched 3.5mm jack socket. Vertical panel mounting with solder tags. Supplied with ring nut.

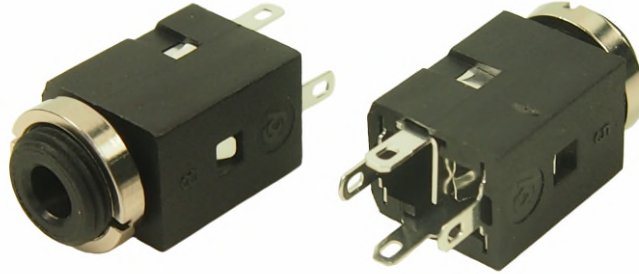

Part No. **FC681374V**

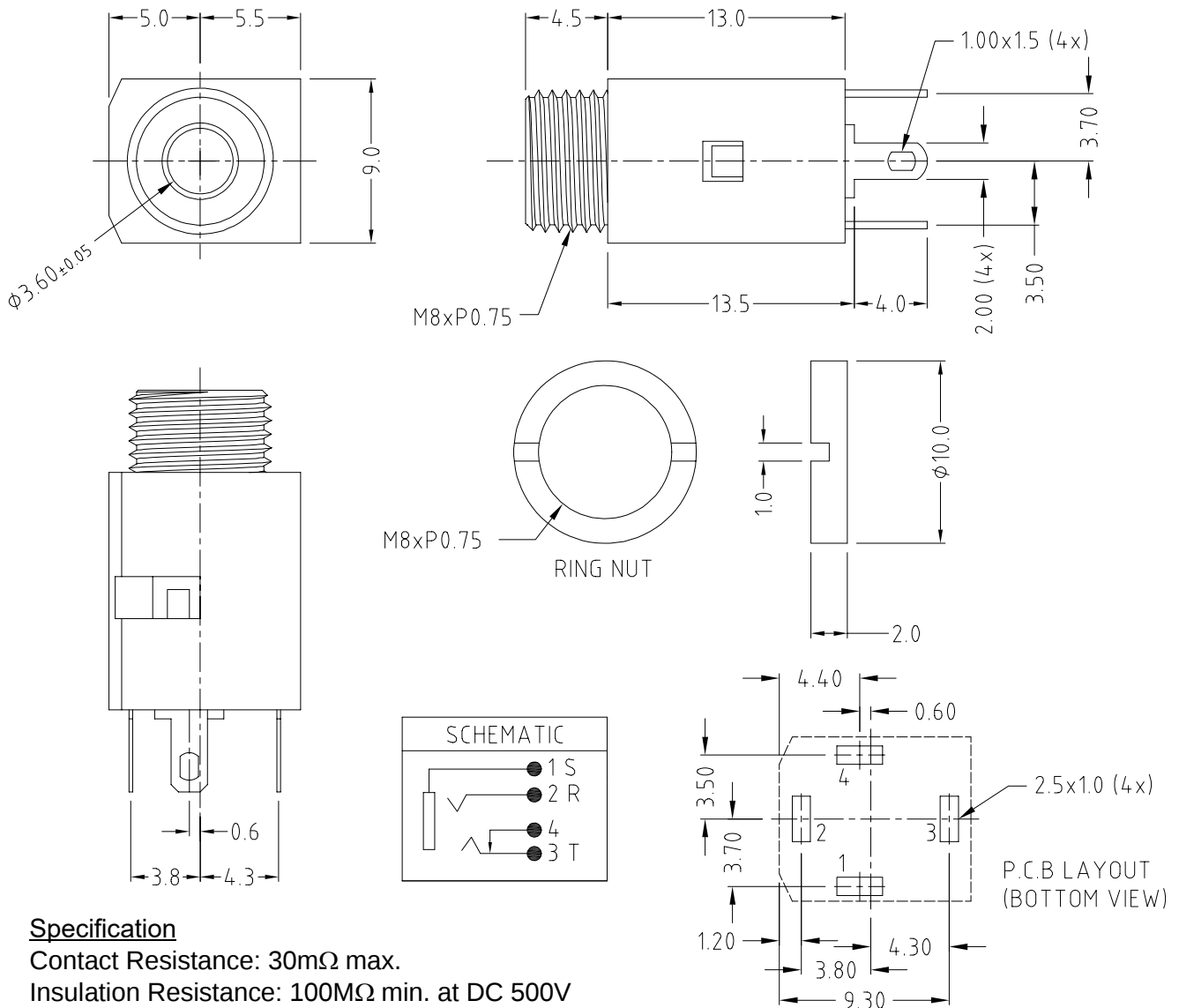

Specification

Contact Resistance: 30m Ω max.

Insulation Resistance: 100M Ω min. at DC 500V

Dielectric Withstand Voltage: AC 500V for 1 minute