

IEC-connector / IEC-Stecker / Kuppler

High shielded IEC connectors (DIN 45325) / Hochgeschirmte IEC-Stecker / Kuppler:

CKS 4-00 (IEC-male) & CKK 4-00 (IEC-female), right angel

CKS 5-00 (IEC-male) & CKK 5-00 (IEC-female), axial

Operational data / Betriebsdaten:

Impedance / Impedanz:

75 Ω

Frequency range / Frequenzbereich:

0-2400 MHz

Screening factor / Schirmungsmass:


EN 50083-2/A1 Klasse A / Class A

Connectors / Anschlüsse:


IEC male / femaleF

CE


Typical measured values / Typische Meßwerte:

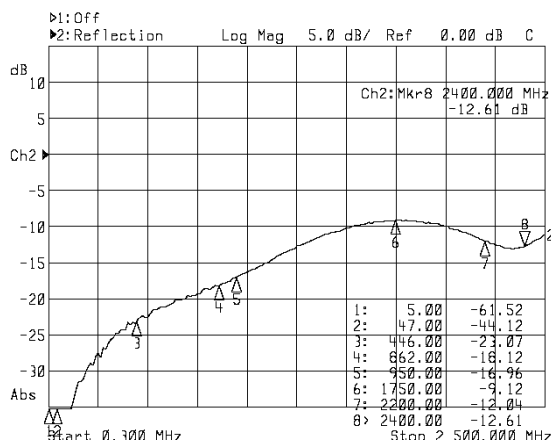


top: Return loss CKS 4-00

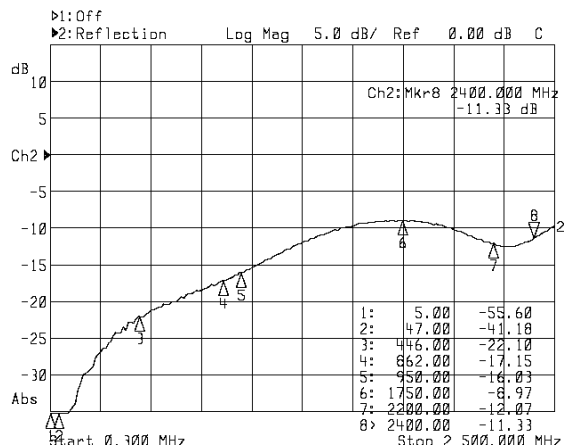

top: Return loss CKK 4-00

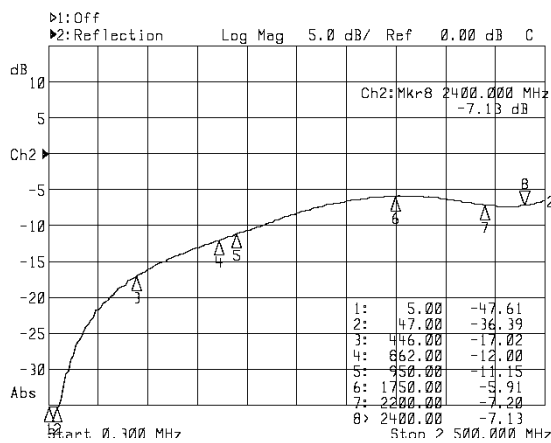


top: Return loss CKS 5-00

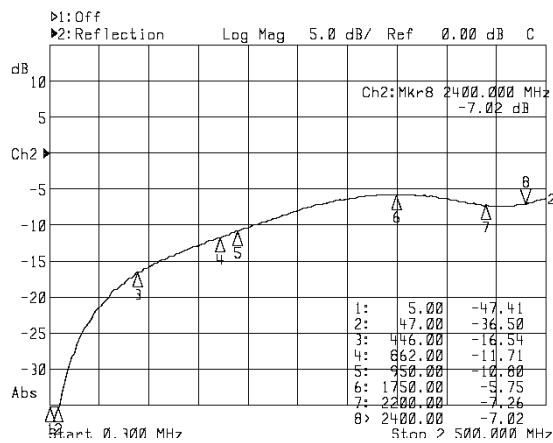


top: Return loss CKK 5-00

IEC-connector / IEC-Stecker / Kuppler

Screening CKS / CKK 4-00:

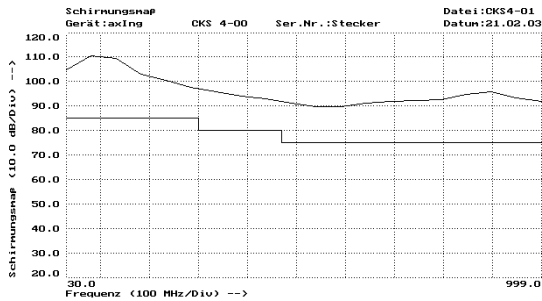


top: CKS 4-00

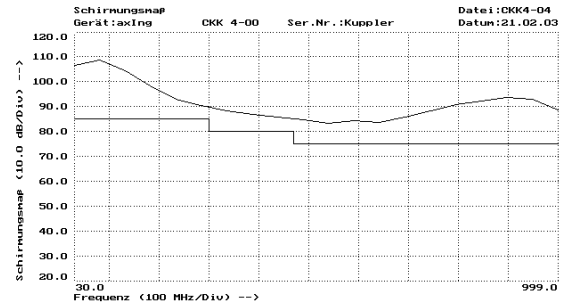


top: CKK 4-00

Screening CKS / CKK 5-00:

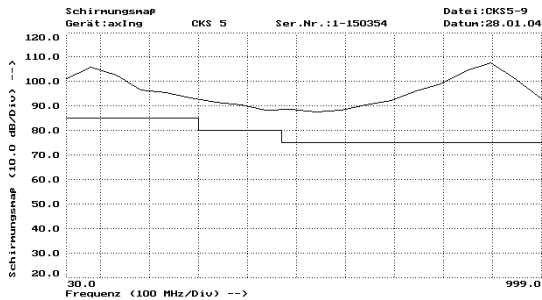

top: CKS 5-00

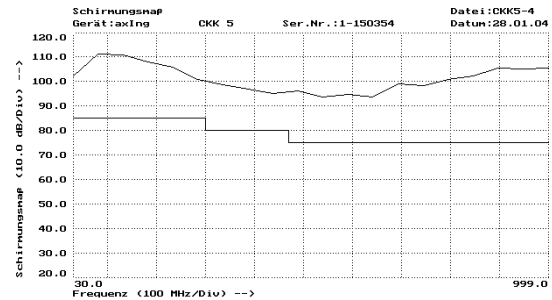

top: CKK 5-00