



HT-22/8

Order No.: 10.0180

PRODUCTINFOS

Cone tweeter, 10 W, 8 Ω

- Classic tweeter for hi-fi, car hi-fi and for replacement purposes

Klang+Ton 02/2012

"The unit at the most favourable price was the surprise in the test ... provides the most balanced frequency response in front of the microphone ... very attractive price, to be used without any problems, offers best measured values."

TECHNICAL SPECIFICATIONS

HT-22/8

Impedance (Z)

8 Ω

HT-22/8



Operating voltage	-
Frequency range	fx-19000 Hz
Resonant frequency (fs)	1500 Hz
Rec. crossov. frequ. (fmax.) (12 dB/oct.)	2500 Hz
Power rating	10 W
Peak music power output	20 W
Sensitivity	91 dB/W/m
Max. rated SPL	-
Max. voltage	-
Radiation angle, horizontal	-
Radiation angle, vertical	-
Suspension compl. (Cms)	-
Moving mass (Mms)	-
Mech. Q factor (Qms)	-
Electr. Q factor (Qes)	-
Total Q factor (Qts)	-
Equivalent volume (Vas)	-
DC resistance (Re)	-
Force factor (BxL)	-
Voice coil induct. (Le)	-
Voice coil diameter	Ø12 mm
Voice coil former	-
Linear excursion (X _{MAX})	-
Eff. cone area (Sd)	-
Magnet weight	-
Magnet diameter	Ø45 mm
Mounting cutout	Ø63 mm
Mounting depth	27,4 mm
Mounting hole diameter	Ø80 mm
Hole spacing X-axis	56 mm
Hole spacing Y-axis	56 mm
Dimensions	Ø 90 mm x 28 mm
Outside diameter	Ø90 mm
Width	Ø90 mm
Height	-
Depth	28 mm
Protective class	-

HT-22/8

Admiss. ambient temp.	0-40 °C
Weight	0,17 kg
Sales unit	1
Type of speaker	2"

* **Important Notice:** The retail prices shown here are non-binding recommendations that retailers can charge their customers. They are not part of any specific offer or advertisement. These prices include all charges as well as VAT, but do not cover any additional delivery and shipping costs. Our latest price lists for the retail market include all applicable delivery and payment terms for retailers.

HT-22/8

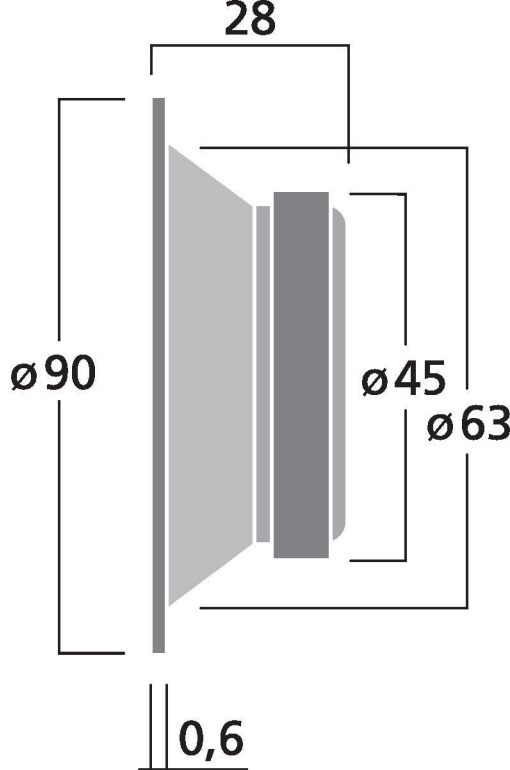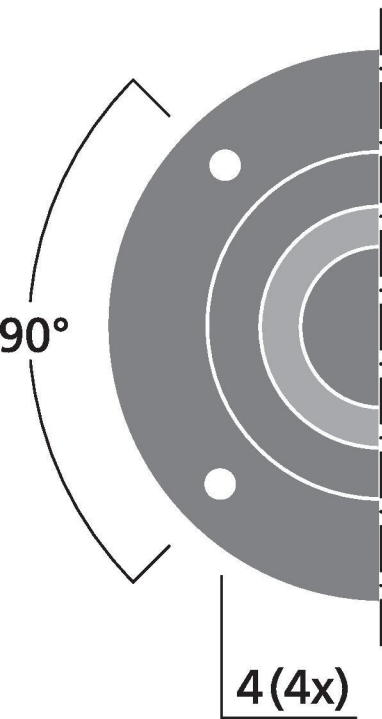

HT-22/8 (10.0180)

