

ENERGIZER 522 (LR61)

Alkaline Power




9V

Specifications


Classification:	Alkaline
Chemical System:	Zinc-Manganese Dioxide (Zn/MnO ₂) No added mercury or cadmium
Designation:	ANSI 1604A, IEC-6LF22 or 6LR61
Nominal Voltage:	9.0 volts
Operating Temp:	-18°C to 55°C
Typical Weight:	46.0 grams
Typical Volume:	21.0 cubic centimeters
Jacket:	Metal
Shelf Life:	5 years at 21°C
Terminal:	Miniature Snap

Industry Standard Dimensions

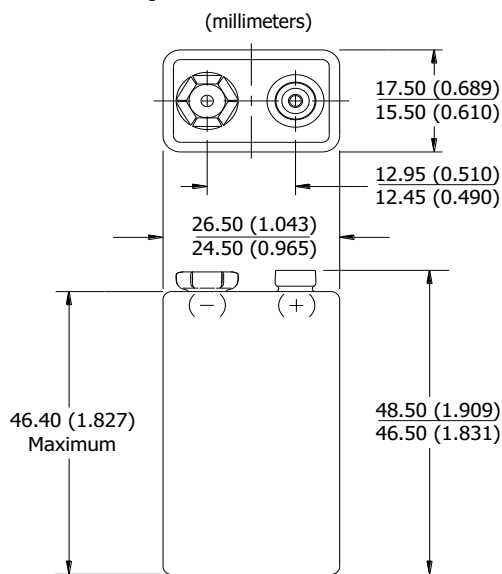

Performance Comparison

A522 vs. Typical Carbon Zinc (9V) at 21°C

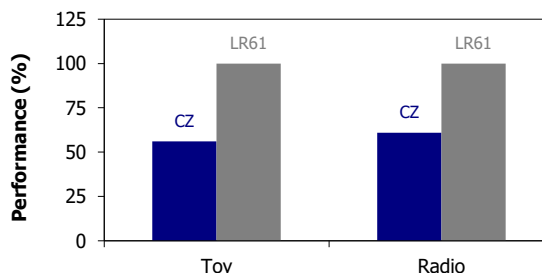

Industry Standard Testing Protocol

Device Selection Guide:

Toy



Baby Monitor



Garage Opener




Clock Radio



Smoke Detector



Battery Selection Indicator

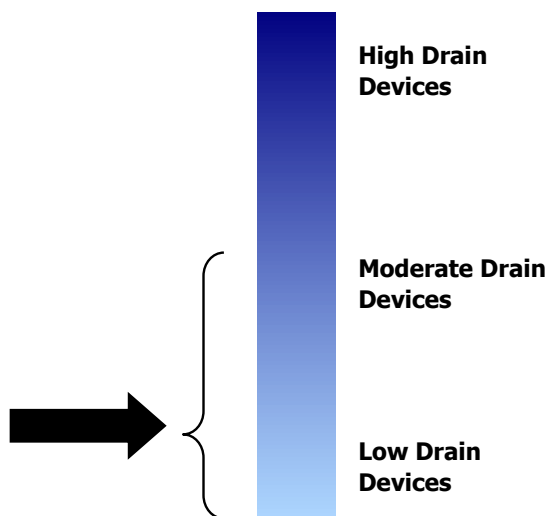

Important Notice

This data sheet contains typical information specific to products manufactured at the time of its publication.
Contents herein do not constitute a warranty and are for reference only.