


ENERGIZER E93 (LR14)

Alkaline Power



Industry Standard Dimensions

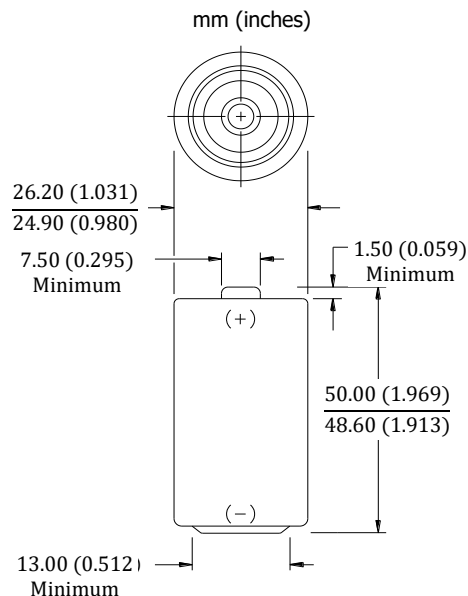


General Information

Classification:	Alkaline
Chemical System:	Zinc-Manganese Dioxide (Zn/MnO ₂) No added mercury or cadmium
Designation:	ANSI-14A, IEC-LR14
Nominal Voltage:	1.5 volts
Operating Temp:	-18°C to 55°C (0°F to 130°F)
Typical Weight:	66 grams
Typical Volume:	27 cubic centimeters
Shelf Life:	7 years at 21°C
Terminal:	Flat Contact

Performance Comparison

A93 vs. Typical Carbon Zinc (C) at 21°C

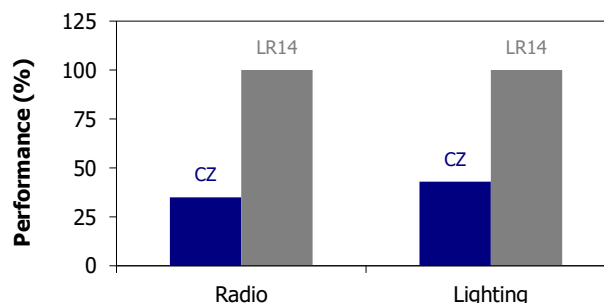

Industry Standard Testing Protocol

Device Selection Guide:

Portable Stereo



Toy




Lighting



Radio



Battery Selection Indicator

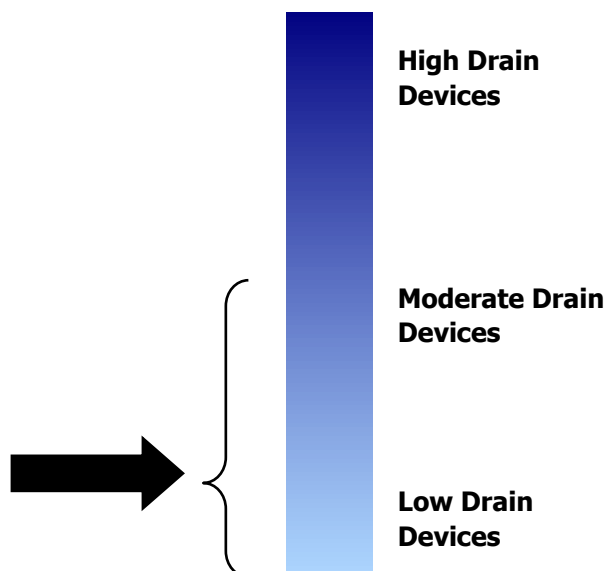

Important Notice

This datasheet contains typical information specific to products manufactured at the time of its publication.
Contents herein do not constitute a warranty and are for reference only.