


ENERGIZER E95 (LR20)

Alkaline Power

D



Industry Standard Dimensions

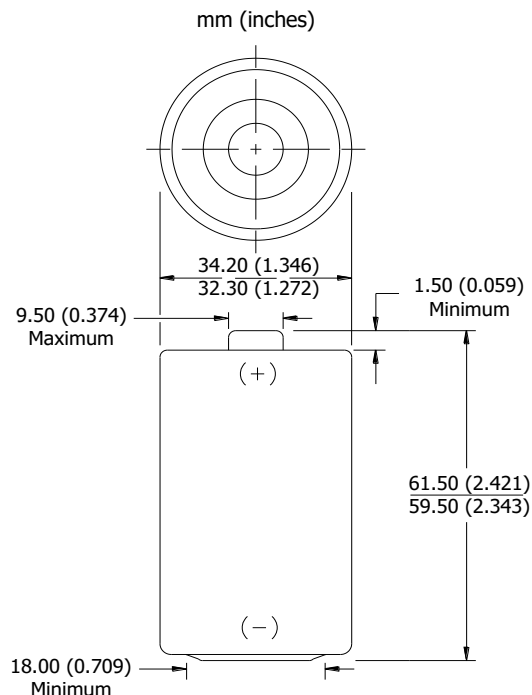


General Information

Classification:	Alkaline
Chemical System:	Zinc-Manganese Dioxide (Zn/MnO ₂) No added mercury or cadmium
Designation:	ANSI-13A, IEC-LR20
Nominal Voltage:	1.5 volts
Operating Temp:	-18°C to 55°C (0°F to 130°F)
Typical Weight:	139 grams
Typical Volume:	56 cubic centimeters
Shelf Life:	7 years at 21°C
Terminal:	Flat Contact

Performance Comparison

A95 vs. Typical Carbon Zinc (D) at 21°C

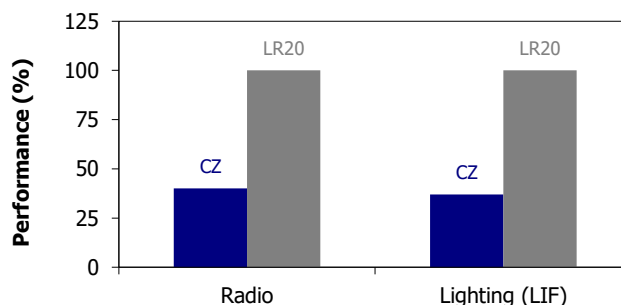

Industry Standard Testing Protocol

Device Selection Guide:

Portable Stereo



Toy




Lighting



Radio



Battery Selection Indicator

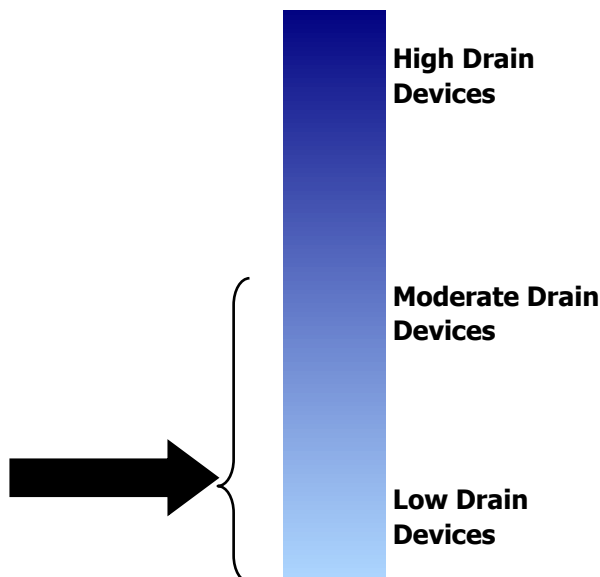

Important Notice

This datasheet contains typical information specific to products manufactured at the time of its publication.
Contents herein do not constitute a warranty and are for reference only.