

ENERGIZER 522


9V



Specifications


Classification:	Alkaline
Chemical System:	Zinc-Manganese Dioxide (Zn/MnO ₂) No added mercury or cadmium
Designation:	ANSI 1604A, IEC-6LF22 or 6LR61
Nominal Voltage:	9.0 volts
Operating Temp:	-18°C to 55°C
Typical Weight:	45 grams
Typical Volume:	21 cubic centimeters
Shelf Life:	5 years at 21°C
Terminal:	Miniature Snap

Industry Standard Dimensions



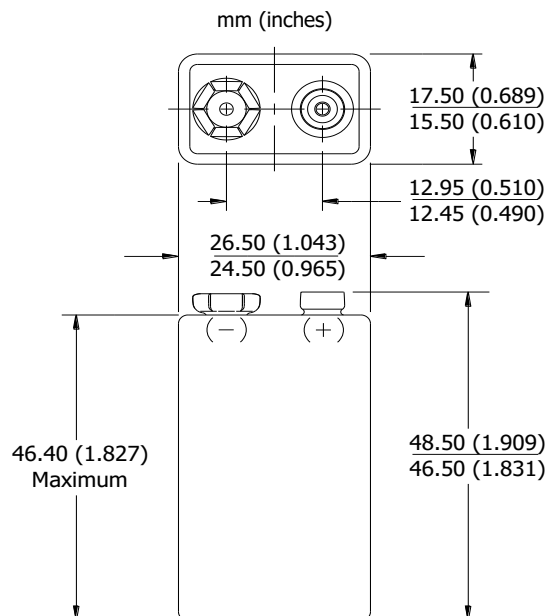


Milliamp-Hours Capacity

Continuous discharge to 4.8 volts at 21°C

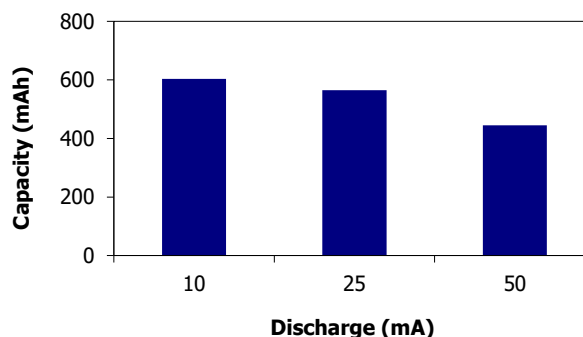

Industry Standard Tests (21°C)

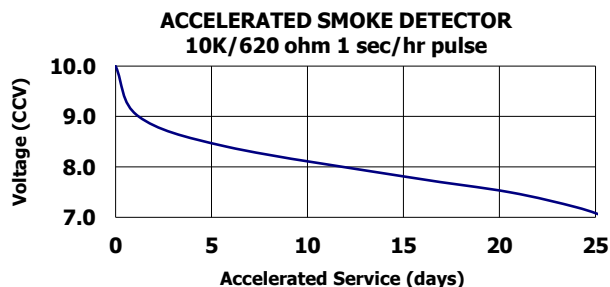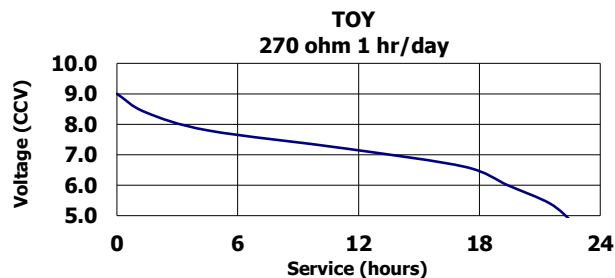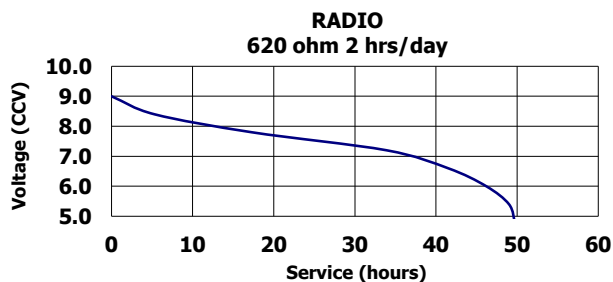

Important Notice

This data sheet contains typical information specific to products manufactured at the time of its publication.

Contents herein do not constitute a warranty and are for reference only.