

ENERGIZER A27



ZEROMERCURY®


Miniature Alkaline

Specifications

Classification:	"Miniature Alkaline"
Chemical System:	Manganese Dioxide (MnO ₂)
Designation:	N/A
Nominal Voltage:	12.0 volts
Typical Capacity:	27 mAh to 6.0 volts (rated at 20k ohms at 21°C)
Typical Weight:	4.4 grams (0.2 oz)

Industry Standard Dimensions

mm (inches)

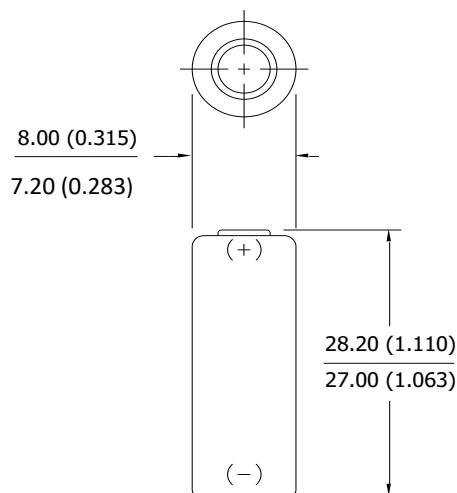

**Designed for electronic applications
which may require high rate pulses**


Typical Discharge Durations

at 21°C

Schedule (time)	Drain (mA)	Load (ohms)	Cutoff Voltage		
			8.8V (hours)	7.2V (hours)	6.0V (hours)
Continuous	0.5	20K	49	54	55

Discharge Characteristics

Schedule: Continuous
Typical Load: 20K ohms (21°C)

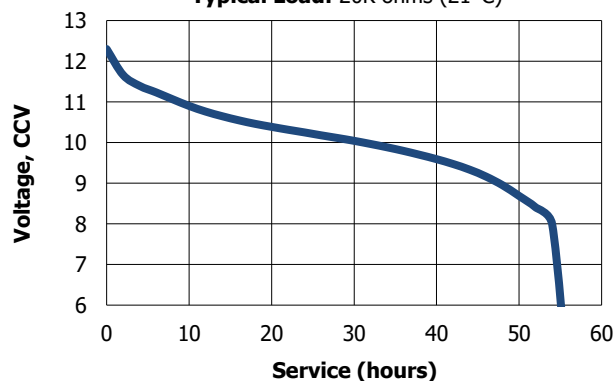

Important Notice

This datasheet contains typical information specific to products manufactured at the time of its publication.
Contents herein do not constitute a warranty and are for reference only.