

DIGITUS[®] CAT 6_A, Class E_A Desktop Patch Panel, shielded



✓ Category: 6_A

✓ Shielded

✓ 12-port

✓ For SoHo applications

Abstract

DIGITUS[®] CAT 6_A, Class E_A Desktop Patch Panel, shielded, 1U, 12-port, color black (RAL 9005)


Features

- Class E_A, up to 500 MHz, ISO IEC 11801, EN 50173
- 10 Gbit Ethernet
- Material housing: SECC, 1.5 mm galvanized, cold-rolled steel acc. EN1.4301
- Shielded RJ45 jacks, 8P8C
- Cable installation via LSA strips, color coded according to EIA/TIA 568 A & B
- Fixing option for cable ties, central ground connection
- Central ground connection
- Desktop version for SoHo applications (Small Office, Home Office)


Product Overview

The Desktop Patch Panels from DIGITUS[®] are the ideal solution for SoHo applications (Smart Office, Home Office), where 10 Gbit are required.

Product Images

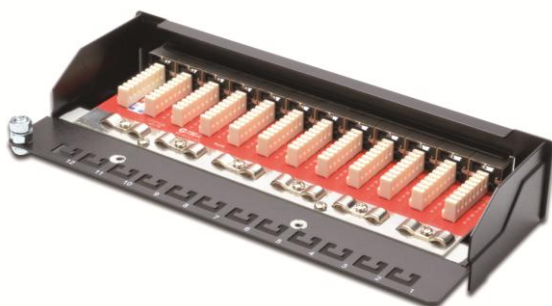

Technical Drawings

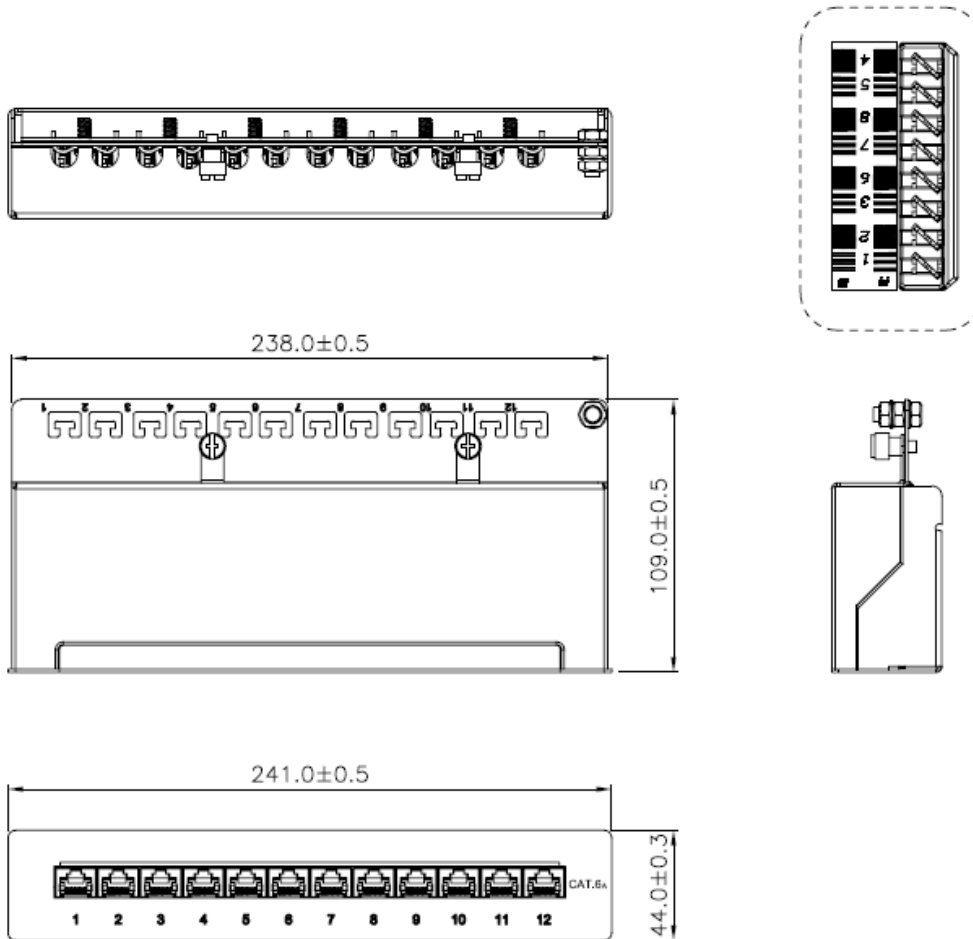

Product Number Information

DN-91612SD-EA DIGITUS® CAT 6_A, Class E_A, Desktop Patch Panel, shielded, 12-port RJ45, 8P8C, LSA

More Desktop Patch Panels from DIGITUS®

DN-10001 DIGITUS® CAT 5e Desktop Patch Panel, shielded, 8x fully shielded RJ45 connectors
 DN-91608SD DIGITUS® CAT 6 Desktop Patch Panel, shielded, Class E, 8-port RJ45, 8P8C, LSA, color black (RAL 9005)

Product Number Information - Accessories

DN-LSA-PT DIGITUS® LSA Punch Down Tool
 DN-94014 DIGITUS® Pliers, cutting area 0.7 mm hole, for precise and easy cutting, compact design, with ergonomic handle (yellow)
 DN-94015 DIGITUS® Cutter & Stripper, 5" electrical cutter & stripper for flush cutting, size 20-24 AWG
 DN-CT-10M-20 Velcro Tape, 20 mm wide, for structured cabling, 10 m roll, color black