


NOTE:

- 1. 100% open short & miss wire test;
- 2. Unmarked tolerance dimension on the basis of SJ/T10628—1995 6 grade;
- 3. Storage Temperature: -40°C~+70°C  
Operation Temperature: -10°C~+60°C  
Operation humidity: 10%~85%  
Storage humidity: 10%~85%
- 4. RoHS 3.0 and REACH Compliant

PIN OUT

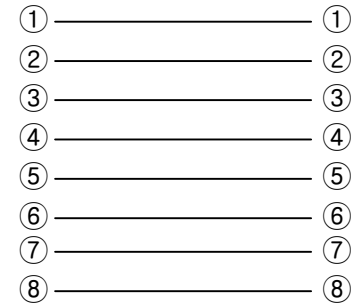

MATERIAL LIST:

⑥	Contact	8P8C 3U" Gold Plated	8	
⑤	Base	ABS	1	
④	roof cover	ABS	1	
③	shielded enclosure	Nickel Plated brass t=0.3mm	2	
②	PCB	FR-4, t=0.8	1	
①	PCB outlet	PBT	2	
NO	MAT. NAME	DESCRIPTION	QT'Y	REMARK

Renkforce					
CUSTOMER		BN.	1381787		
PRODUCT NAME	8P8C RJ45 STP CAT. 5E Connector		UNIT	MM	
DRAWNBY	CHECKBY	APPOBY	DATE		
Hasia	Alvan		2013/07/11		

		NEW	2013/07/11	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.