




Male plug

0935 52

10971

Technical modifications reserved

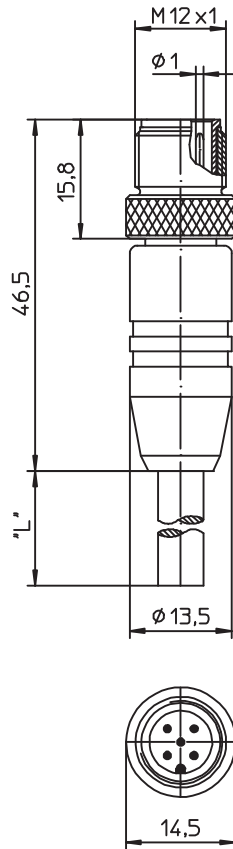

Catalog type: 0935 XXX 104...

- Male plug with moulded cable

1. Operating temperature range : -25 °C / +80 °C

2. Material data

Body	: TPU
Insert	: TPU
Contact	: CuSn, pre-nickeled and gold-plated
Knurled screw	: CuZn, pre-nickeled

3. Mechanical data

Degree of protection *	: IP67
Good chemical resistance	
Resistance needs to be approved in special cases	

 
4. Electrical data

Contact resistance R_d	: $\leq 5 \text{ m}\Omega$
Nominal current I_n at 40° C	: 4 A
Rated voltage U_n	: 60 V
Test voltage U_p	: 1,5 kV_{eff} / 60 s
Insulation resistance R_{is}	: $> 10^9 \Omega$
Degree of pollution	: 3

* Only in fully locked position with its plugs

"L" = Standard cable length

Additional technical data of the cable 909...

Type	Standard - Contact - Configuration	
	Poles	Colour code
0935 XXX 104/...	5	 <p>1 = Drain 2 = red 3 = black 4 = white 5 = blue</p>

lumbergautomation
A BELDEN BRAND

date	name	edit.	1								
iss.	04.02.08	se	name	Voc							
appr.	14.01.14	Rück	date	14.01.14							

Technical specification sheet

no. of modification

sheet
of 1