


WALLAIR 

W-Style RE Premium 150

24W - 312m³/h - 57 Pa - 46dB(A)
220-240V~ 50/60Hz - Temp 50°C - IPX4

Axial-Lüfter Ø 150 mm
mit kugelgelagertem Motor
Axial fan Ø 150 mm with ball bearing motor
Aérateur hélicoïde Ø 150 mm
moteur avec roulements à bille
Aspiratore assiale Ø 150 mm
con motore a cuscinetti

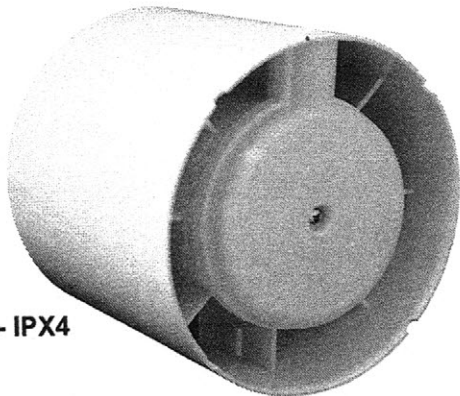

000949



Ringelblende
Produktüber-
wachung
Sicherheit
Bauart geprüft
www.tuv.com
© 11106060

4" 046293 " 409041 "

N40904