

PRODUCT SPECIFICATION

Brand	Kasp
Product Range	Premium brass padlocks
Catalogue number	120
Date	16/01/2017

Range Description
Premium brass padlocks

Features

- Hardened steel shackle (30mm and above) – extra protection against hacksaw and cropping attacks
- Double bolted locking mechanism (30mm and above) – extra strength to resist torsion and pull attacks
- Solid brass body – added resistance to corrosion

Derivatives

- Long shackle – provides greater shackle clearance for versatility
- Brass shackle – anti spark and added resistance to corrosion
- Stainless steel shackle - maximum resistance against corrosion


Weather rating: 1



120 series



Long shackle

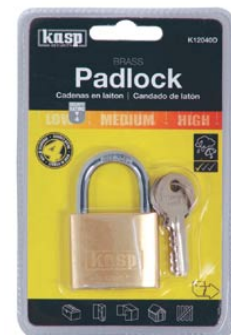

Item Number	Item Description	EAN No	Commodity code	Carton Qty
K12020	Brass padlock 20mm - boxed	5013969900057	83011000	12
K12020D	Brass padlock 20mm - display packed	5013969900064	83011000	6
K12020D2	Brass padlock 20mm – twin pack	5013969750010	83011000	12
K12025	Brass padlock 25mm – boxed	5013969900071	83011000	12
K12025D	Brass padlock 25mm – display packed	5013969900095	83011000	6
K12025D2	Brass padlock 25mm – twin pack	5013969750027	83011000	12
K12025A1	Brass padlock 25mm KA20251– boxed	5013969900088	83011000	12
K12025LO	Brass padlock 25mm – lockout	5013969904536	83011000	12
K12030	Brass padlock 30mm – boxed	5013969900101	83011000	12
K12030D	Brass padlock 30mm – display packed	5013969900125	83011000	6
K12030D2	Brass padlock 30mm – twin pack	5013969750034	83011000	6
K12030A1	Brass padlock 30mm KA20301 – boxed	5013959900118	83011000	12
K12030L70BD	Brass padlock 30mm with 70mm long brass shackle – display packed	5013969750102	83011000	6
K12040	Brass padlock 40mm – boxed	5013969900132	83011000	12
K12040D	Brass padlock 40mm – display packed	5013969900156	83011000	6
K12040D2	Brass padlock 40mm – twin pack	5013969750041	83011000	6
K12040D4	Brass padlock 40mm – quad pack	5013969750058	83011000	4
K12040A1	Brass padlock 40mm KA20401 – boxed	5013969900149	83011000	12
K12040L40D	Brass padlock 40mm with 40mm long shackle – display packed	5013969750089	83011000	6
K12040L63D	Brass padlock 40mm with 63mm long shackle – display packed	5013969750072	83011000	6
K12040L55D	Brass padlock 40mm with 55mm long shackle – display packed	5013969900170	83011000	6
K12040L55A1	Brass padlock 40mm with 55mm long shackle KA – boxed	5013969900163	83011000	6
K12050	Brass padlock 50mm – boxed	5013969900187	83011000	6
K12050D	Brass padlock 50mm – display packed	5013969900200	83011000	6
K12050D2	Brass padlock 50mm – twin pack	5013969750065	83011000	6
K12050A1	Brass padlock 50mm KA20501 – boxed	5013969900194	83011000	6
K12050L80D	Brass padlock 50mm with 80mm long shackle – display packed	5013969750096	83011000	6
K12050SD	Brass padlock 50mm with stainless steel shackle – display packed	5013969750119	83011000	6
K12060	Brass padlock 60mm – boxed	5013969900224	83011000	6
K12060D	Brass padlock 60mm – display packed	5013969900248	83011000	6
K12060A1	Brass padlock 60mm KA20601 – boxed	5013969900231	83011000	6

Technical product information

Body – Solid brass

Locking mechanism- Pin tumbler cylinder type

Security rating, key differs and Use environment:

Item	Security rating	Key differs	Pins	Use Environment
K12020	2	6	3	Light outdoor use
K12025	2	8	3	Light outdoor use
K12030	3	96	4	Light outdoor use
K12040	4	504	5	Light outdoor use
K12050	6	1800	5	Light outdoor use
K12060	8	1800	5	Light outdoor use

Shackle Dimensions and materials:

Dimensions mm	Dia	Internal width	Internal height	Material
K12020	3	10	13	Steel
K12025	4	12	15	Steel
K12030	5	16	18	Hardened steel
K12030L70BD	5	16	70	Brass
K12040	6	22	22	Hardened steel
K12040L40D	6	22	40	Hardened steel
K12040L55D	6	22	55	Hardened steel
K12040L63D	6	22	63	Hardened steel
K12050	8	28	30	Hardened steel
K12050L80D	8	28	80	Hardened steel
K12050SD	8	28	30	Stainless Steel
K12060	9.5	34	36	Hardened steel

Recommended applications- Luggage, cupboards, lockers, toolboxes, sheds etc.

Standards compliance	None applicable
User health and safety information	None applicable
RoHS/WEEE compliance	This product range does not fall within the scope of RoHS or WEEE regulations
Material safety data	None applicable
Warranty	KASP padlocks are guaranteed against defects in manufacture and/or materials for 10 years Damage caused through inappropriate use or attempted break in is not covered
Country of origin	China

Dimensional details

Item	Product only				Product on primary packaging			
	Width mm	Depth mm	Height mm	Net weight g	Width mm	Depth mm	Height mm	Gross weight g
K12020	20	10	36	31	28	12	46	32
K12020D	20	10	36	31	70	16	115	40
K12020D2	20	10	36	31	110	15	134	73
K12025	25	10	45	46	28	14	46	47
K12025D	25	10	45	46	70	16	115	56
K12025D2	25	10	45	46	100	15	154	110
K12025A1	25	10	45	46	28	14	46	47
K12025LO	25	10	45	46	80	18	157	70
K12030	30	13	54	98	35	17	61	99
K12030D	30	13	54	98	77	22	120	97
K12030D2	30	13	54	98	100	20	154	183
K12030A1	30	13	54	98	35	17	61	99
K12030L70BD	30	13	104	102	100	19	192	121
K12040	40	15	63	160	47	21	72	165
K12040D	40	15	63	160	100	19	155	179
K12040D2	40	15	63	160	150	22	150	306
K12040D4	40	15	63	160	214	22	150	599
K12040A1	40	15	63	160	47	21	72	165
K12040L40D	40	15	80	164	100	23	154	168
K12040L55D	40	15	96	175	100	21	155	194
K12040L55A1	40	15	96	175	46	19	110	182
K12040L63D	40	15	103	175	98	23	190	186
K12050	50	17	79	271	55	20	85	278
K12050D	50	17	79	271	100	23	155	297
K12050D2	50	17	79	271	150	23	150	527
K12050SD	50	17	79	271	100	23	155	274
K12050L80D	50	17	127	315	98	23	190	311
K12050A1	50	17	79	271	55	20	85	278
K12060	60	19	90	415	64	21	95	424
K12060D	60	19	90	415	110	24	160	440
K12060A1	60	19	90	415	64	21	95	424

Item	Shelf box (secondary packaging)				Euro Pallet data Wi x Hi	
	Width mm	Depth mm	Height mm	Gross weight g	No of cartons on base	Number of rows high
K12020	62	80	45	399		
K12020D	80	175	45	284		
K12020D2	229	100	91	961		
K12025	62	85	45	579		
K12025D	80	185	55	384		
K12025D2	162	105	179	1402		
K12025A1	62	85	45	579		
K12025LO						
K12030	75	110	67	1221		
K12030D	80	190	55	697		
K12030D2	160	105	110	1171		
K12030A1	75	110	67	1221		
K12030L70BD	225	105	91	794		
K12040	95	135	80	2037		
K12040D	105	255	60	1158		
K12040D2	170	165	120	1919		
K12040D4	220	165	70	2475		
K12040A1	95	135	80	2037		
K12040L40D	190	105	80	1052		
K12040L55D	105	270	60	1249		
K12040L63D	228	105	90	1181		
K12040L55A1	120	115	50	1120		
K12050	90	135	57	1654		
K12050D	105	260	65	1867		
K12050SD	160	110	108	1709		
K12050D2	170	155	119	3251		
K12050L80D	226	105	90	1918		
K12050A1	90	135	57	1654		
K12060	100	145	65	2578		
K12060D	115	170	145	2737		
K12060A1	100	145	65	2578		

Packaging waste details

Item	Primary Packaging				Secondary packaging			
	Plastic g	Use	Card g	Use	Plastic g	Use	Card g	Use
K12020			1	Box			15	Box
K12020D	6	Blister	3	Backing card			44	Box
K12020D2	8		3				85	Box
K12025			1	Box			15	Box
K12025D	7	Blister	3	Backing card			48	Box
K12025D2	9		4				85	Box
K12025A1			1	Box			15	Box
K12030			1	Box			33	Box
K12030D	7	Blister	3	Backing card			49	Box
K12030D2	9		4				65	Box
K12030A1			1	Box			33	Box
K12030L70BD	4	Blister	4	Backing card			120	Box
K12040			5	Box			57	Box
K12040D	14	Blister	5	Backing card			84	Box
K12040D2	16		6				95	Box
K12040D4	26		8				85	Box
K12040A1			5	Box			57	Box
K12040L40D	12	Blister	3	Backing Card			100	Box
K12040L55D	14	Blister	5	Backing card			85	Box
K12040L55A1			7	Box			28	Box
K12040L63D	12	Blister	3	Backing Card			120	Box
K12050			7	Box			28	Box
K12050D	17	Blister	7	Backing card			85	Box
K12050D2	16		6				95	Box
K12050A1			7	Box			28	Box
K12050L80D	15	Blister	4	Backing Card			120	Box
K12050SD	12	Blister	3	Backing Card			120	Box
K12060			9	Box			34	Box
K12060D	17	Blister	17	Backing card			97	Box
K12060A1			9	Box			34	Box

