


### Conductive Aluminum Foil Tape

Version 09/15

Item no. 1386782, 1386783

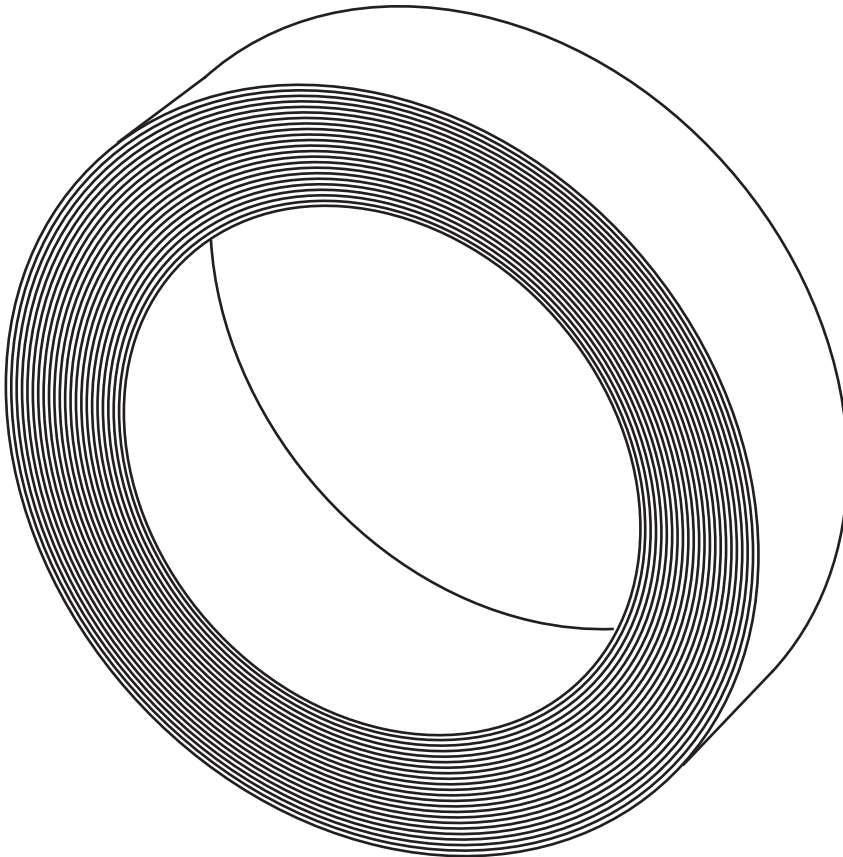

#### Specification

Backing	: Aluminum
Adhesive	: Conductive Acrylic
Backing thickness	: 0.025±0.005mm
Adhesive thickness	: 0.055±0.005mm
Total thickness	: 0.08± 0.01mm
Color	: Aluminum

#### Technical Data

Electrical Resistance	:0.03~0.05ohm
Adhesive power	:1.5kg/25mm
Tensile strength	:>45N/25mm
Ball tack	:#8
Holding power	:1.5kg/25mm
180° peel strength	:>9.8N/25mm
Operating temperature	:-20°C ~ 120°C
Apply temperature	:-10°C ~ 40°C
Storage temperature	:10 ~ 20°C
Storage humidity	:55~65%RH

File no.	Model no.	Length (m)	Width (mm)
1386782	AL-F2.5R1000	10	25
1386783	AL-F5.0R1000	10	50