
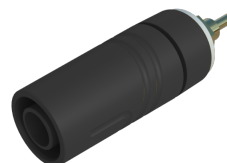


Sockets

SAB 2630 S1,9 Au

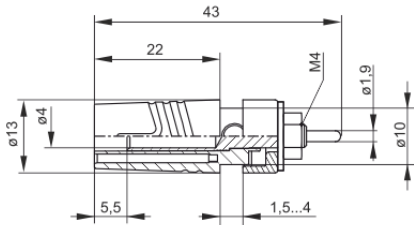

Product	SAB 2630 S1,9 Au
description	Safety surface-mounted socket, 4 mm diameter, contact-protected, gold-plated brass with solder pin Ø 1,9mm. For installation into switch-panels and equipment-chassis of 1-4mm thickness. Connects with safety test leads.
operating instruction	BA456
article-no. / *colour	9723607xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet Au
drawing	
	
technical data	
connection	solder connection pin Ø 1,9 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	24 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25°C °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
 stand: 21.06.2022

stand: 21.06.2022