

D-Sub IDC

Strain relief for Female Connectors



SPECIFICATION:

Current rating: 1 A
Insulation resistance: 1000 M Ω min.
Dielectric voltage: 500 V AC
Operation temperature: -25 °C to +85 °C

MATERIAL:

Insulator: PBT black UL94V-0



HANDLING:

Packing: Bulk

TOLERANCE:

.X \pm 0.38
.XX \pm 0.25

RoHS
COMPLIANT

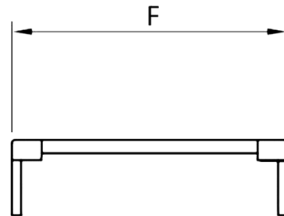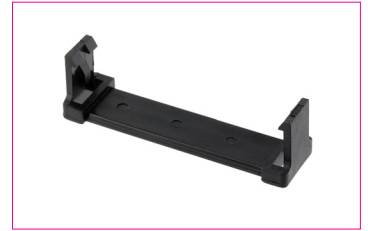

Dimensions

No. of contacts:	F:
9	18.60
15	26.60
25	40.90
37	57.10

Order-Information

Identifier:	No. of contacts:	Version:
ZBU	#	#
Strain relief for D-Sub Female IDC	9: 9 pin 15: 15 pin 25: 25 pin 37: 37 pin	SK/F: for Through Hole SK/FG: for Thread Insert