

**SPECIFICATION:**

Current rating: 1 A  
 Insulation resistance: 1000 MΩ min.  
 Dielectric voltage: 500 V AC  
 Operation temperature: -25 °C to +85 °C

**MATERIAL:**

Insulator: PBT black UL94V-0


**HANDLING:**

Packing: Bulk

**TOLERANCE:**

.X ± 0.38  
 .XX ± 0.25

**RoHS  
COMPLIANT**

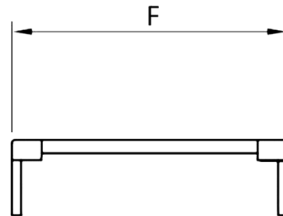

**Dimensions**

No. of contacts:	F:
9	18.60
15	26.50
25	40.90
37	57.10

**Order-Information**

Identifier:	No. of contacts:	Version:
ZST	#	#
Strain relief for D-Sub Male IDC	9: 9 pin	SK/F: for Trough Hole
	15: 15 pin	SK/FG: for Thread Insert
	25: 25 pin	
	37: 37 pin	