

SPECIFICATION:

Current rating: 1 A
 Insulation resistance: 1000 MΩ min.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:


 


Housing: PBT UL94V-0

HANDLING:

Packing: Bulk

TOLERANCE:

.X ± 0.15
 .XX ± 0.10

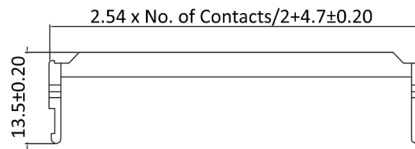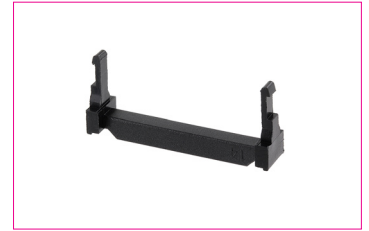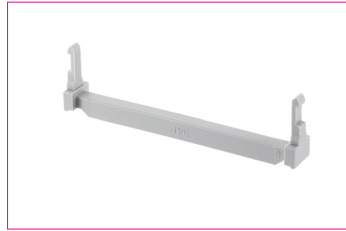

Order-Information

Identifier:	No. of contacts:	Colour:
ZPV	#	#
Strain Relief for IDC Sockets Pitch 2.54 mm	6	empty: black
	8	
	10	GR: grey
	14	
	16	
	20	
	24	
	26	
	34	
	40	
	50	
	60	
	64	