



THIS DRAWING IS UNPUBLISHED. RELEASED FOR PUBLICATION
 © COPYRIGHT - By - ALL RIGHTS RESERVED.

| LOC | DIST | REVISIONS | | | |
|-----|------|-------------|-----------------|-----------|---------|
| P | LTR | DESCRIPTION | DATE | DWN | APVD |
| H | - | A | INITIAL RELEASE | 29NOV2013 | YC BvH |
| | | A1 | ECR-14-015049 | 13OCT2014 | GSK BvH |

NOTES:
 Tolerances cable lengths:
 0m to 0.5m +30mm
 0.5m to 1.0m +50mm
 1.0m to 3.0m +100mm
 < 3.0m +1.5%

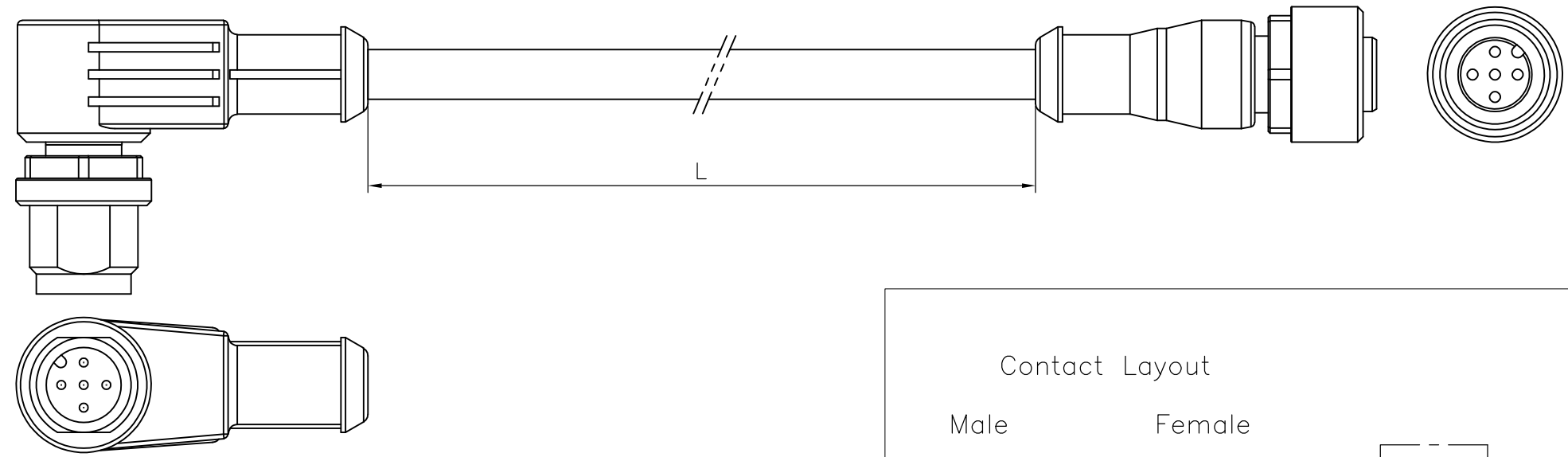

| TECHNICAL DATA | |
|-------------------------------|---|
| Operating voltage | max. 250 V AC/DC |
| Operating current per contact | max. 4 A |
| Locking of ports | Screw thread M12 x 1 mm (recommended torque 0.6 Nm) self-securing |
| Protection | IP65 and IP67 when plugged and screwed down (EN 60529) |

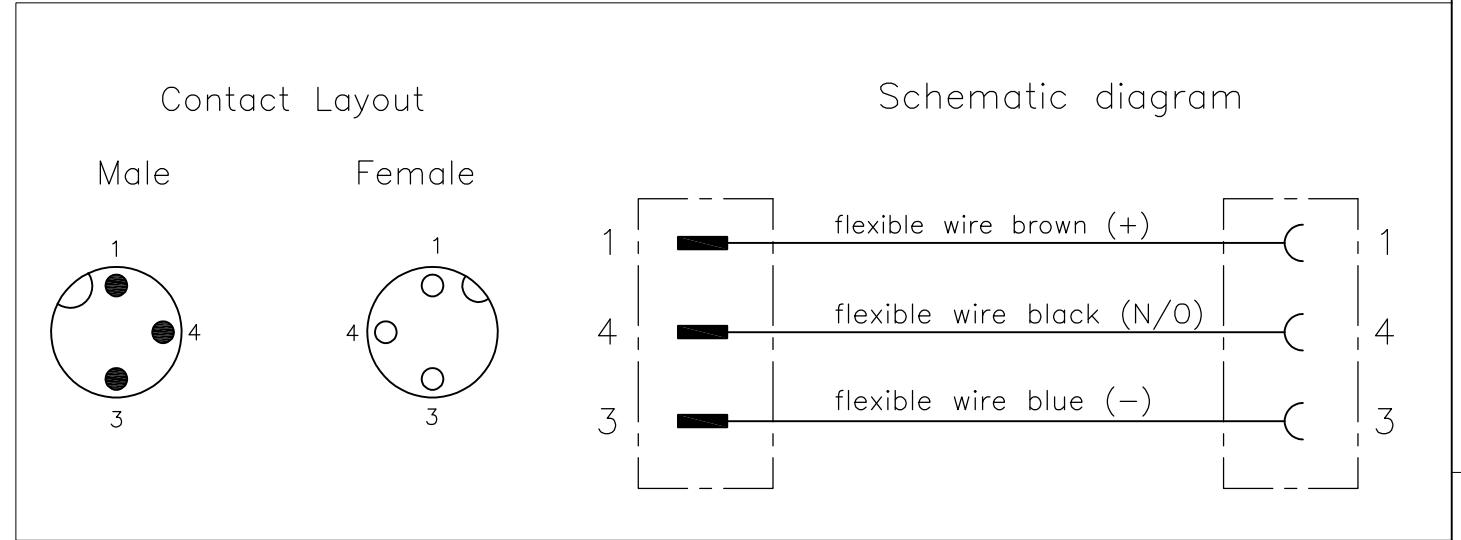

| PUR CABLE | |
|----------------------------|--------------------------|
| No./diameter of wires | 3 x 0.34 mm ² |
| Wire isolation | PP (br, bl, bk) |
| C-track properties | 5 million |
| Jacket | PUR (UL/CSA) |
| Outer diameter | approx. 4.3 mm |
| Bend radius (moving) | 10 x outer diameter |
| Temperature range (fixed) | -40...+80 °C |
| Temperature range (mobile) | -25...+80 °C |

| LENGTH "L" | MATERIAL | JACKET COLOR | TE PN | DESCRIPTION | ITEM |
|------------|----------|--------------|-------------|------------------|------|
| 3 pos | PVC | Black | 1-2273120-5 | 3x22AWG PVC 2.0m | 10 |
| | | | 1-2273120-4 | 3x22AWG PVC 1.5m | 9 |
| | | | 1-2273120-3 | 3x22AWG PVC 1.0m | 8 |
| | | | 1-2273120-2 | 3x22AWG PVC 0.6m | 7 |
| | | | 1-2273120-1 | 3x22AWG PVC 0.3m | 6 |
| 3 pos | PUR | Black | 2273120-5 | 3x22AWG PUR 2.0m | 5 |
| | | | 2273120-4 | 3x22AWG PUR 1.5m | 4 |
| | | | 2273120-3 | 3x22AWG PUR 1.0m | 3 |
| | | | 2273120-2 | 3x22AWG PUR 0.6m | 2 |
| | | | 2273120-1 | 3x22AWG PUR 0.3m | 1 |

| PVC CABLE | |
|----------------------------|--------------------------|
| No./diameter of wires | 3 x 0.34 mm ² |
| Wire isolation | PVC (br, bl, bk) |
| C-track properties | |
| Jacket | PVC (UL/CSA) |
| Outer diameter | approx. 4.6 mm |
| Bend radius (moving) | 10 x outer diameter |
| Temperature range (fixed) | -30...+80 °C |
| Temperature range (mobile) | -5...+80 °C |

THIS DRAWING IS A CONTROLLED DOCUMENT.

| | | | |
|----------------|--|---|----------------------------|
| DIMENSIONS: mm | TOLERANCES UNLESS OTHERWISE SPECIFIED: | DWN YATHISH.C 29NOV2013 | STE TE Connectivity |
| | 0 PLC ± - | CHK B.VELDHOVEN 29NOV2013 | |
| | 1 PLC ± - | APVD A.VAN ZANDVOORT 29NOV2013 | |
| MATERIAL - | FINISH - | NAME M12 ANGLED PLUG TO M12 STRGT SOCKET AA | |
| | | PRODUCT SPEC 108-19483 | RESTRICTED TO - |
| | | APPLICATION SPEC 114-32127 | SIZE A3 |
| | | WEIGHT - | CAGE CODE 00779 |
| | | CUSTOMER DRAWING | DRAWING NO C-2273120 |
| | | | SCALE NTS |
| | | | SHEET 1 OF 1 |
| | | | REV A1 |