

# Flat Cable Connector System DIN 41651 IDC Socket Connectors

Pitch 2.54 mm w/o strain relief



### SPECIFICATION:

Current rating: 1 A  
 Insulation resistance: 1000 MΩ min.  
 Contact resistance: 20 mΩ max.  
 Dielectric voltage: 500 V AC  
 Operation temperature: -40 °C to +105 °C

### MATERIAL:

Housing: PBT UL94V-0  
 Pins: Brass

### FINISH:



Contacts: Gold Flash

### HANDLING:

Packing: Tray

### TOLERANCE:

.X ± 0.15  
 .XX ± 0.10

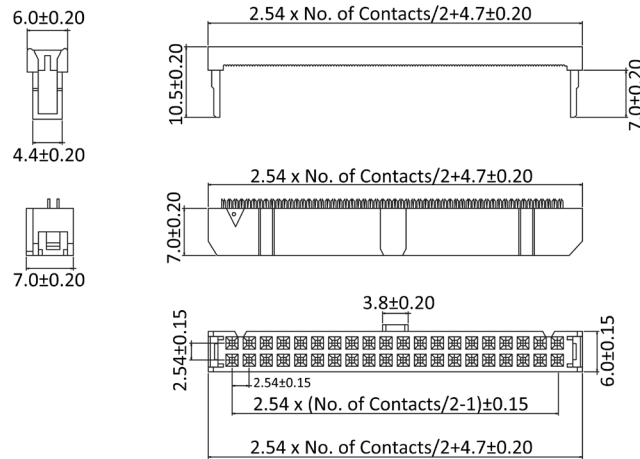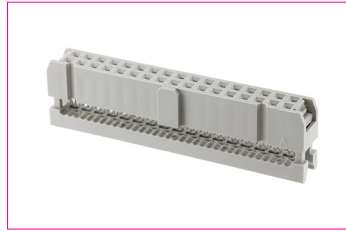

### Order-Information

Identifier:	No. of contacts:	Colour:	Version:
PV	#	#	OZ
IDC Socket Pitch 2.54 mm	6: 2 x 3 8: 2 x 4 10: 2 x 5 14: 2 x 7 16: 2 x 8 20: 2 x 10 24: 2 x 12 26: 2 x 13 34: 2 x 17 40: 2 x 20 50: 2 x 25 60: 2 x 30 64: 2 x 32	empty: black GR: grey	OZ: w/o Strain Relief