

Flat Cable Connector System DIN 41651 Transition Connectors

Pitch 2.54 mm



SPECIFICATION:

Current rating: 3 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 1000 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: PBT UL94V-0
 Pins: Copper alloy



FINISH:

Contacts: Selective gold plated over nickel

HANDLING:

Processing: Wave soldering
 Packing: Tray

RoHS
COMPLIANT

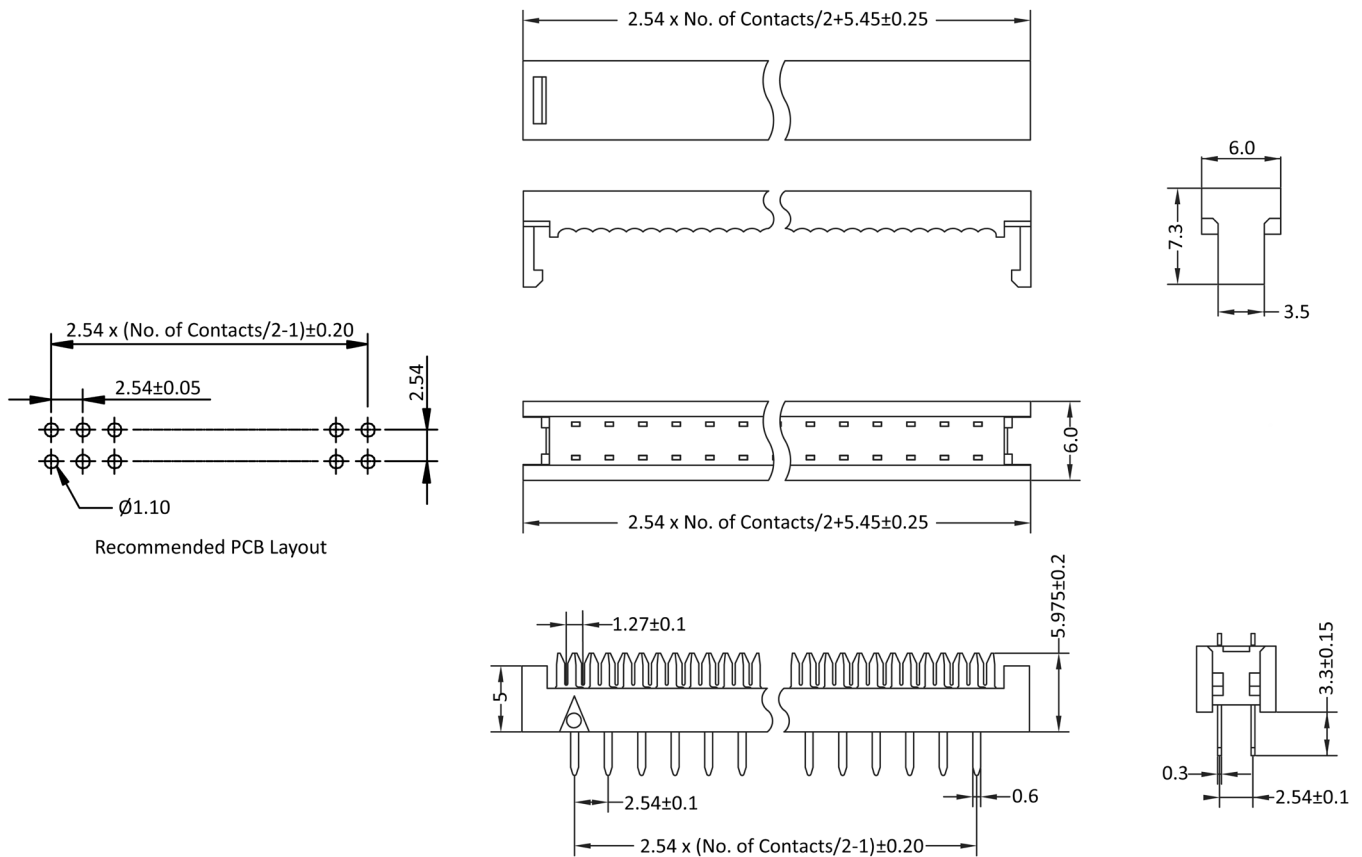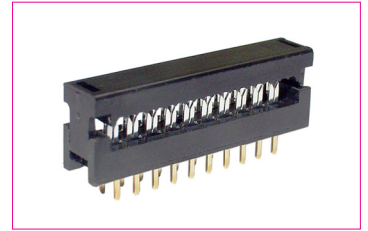

Order-Information

Identifier:	No. of contacts:
LPV25S	#
DIP Plug black pitch 2.54 mm	6: 2 x 3
	8: 2 x 4
	10: 2 x 5
	14: 2 x 7
	16: 2 x 8
	20: 2 x 10
	24: 2 x 12
	26: 2 x 13
	34: 2 x 17
	40: 2 x 40
	50: 2 x 25
	60: 2 x 30
	60: 2 x 32