

NOTES:

Electrical Specifications:

Insulation Resistance: 500M ohms (min.)

Contact Resistance: 20m ohms (max.)

Current Rating : 1.5 Amps.

Withstanding Voltage : 1000 VAC RMS @ 60Hz/ 1 min.

Environmental:

Operation temperature:-10℃ ~+70℃

Storage temperature:-40℃ ~ +85℃

Operation humidity:30%~80%

Storage humidity:30%~80%

weight of unit (w/o packing):39g


Accessory:

1. Screw:STX16 (2PCS)
2. Cable Tie (2Pcs)
3. With Adhesive Tapes For Fixing
4. Instruction Sheet (1PCS)

RoHS2.0 ADN REACH COMPLIANT

PACKING:1PCS/Renkfroce box

PIN OUT:

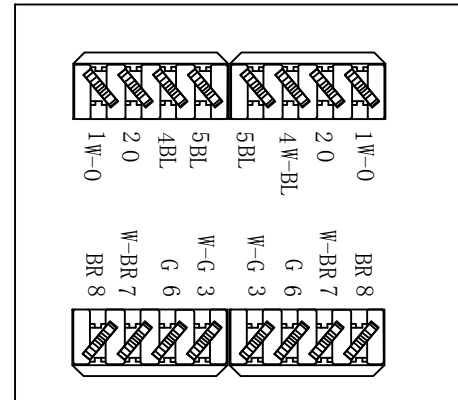

MATERIAL LIST:

⑤	SCREW	ST2.9*5mm	4	
④	PCB	FR-4 (T=1.6)	1	
③	IDC	for AWG 22-26, The pin plated Bronze Tinned	4	
②	Box Base	ABS Chrome Plating	1	
①	Box Cover	ABS Chrome Plating	1	
NO.	PARTS NAME	SPECIFICATION DESCRIPTION	QT'Y	REMARK
		NEW	2015-11-18	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

CUSTOMER		FILE NO.	29212c48		
PRODUCT NAME	CAT.5E STP Connection Box	UNO ITEM NO.	275010	UNIT	MM
DRAWNBY	CHECKBY	APPOBY	DATE		
FERGUS			2015-11-18		