


## Datasheet

### Temperature Probe, -40 to 400 degree C, VOLTCRAFT TP-30

No. 1405076

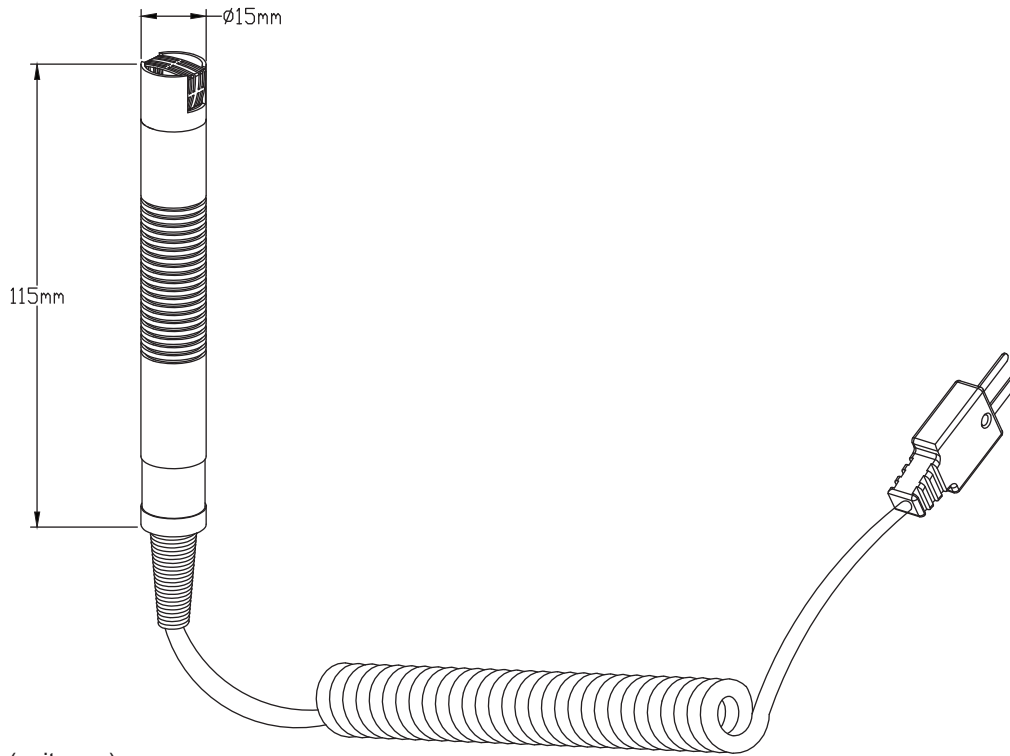

(unit: mm)

#### Technical data

Cable length .....	1.5 m
Contact surface .....	5.5 mm
Response time (details).....	5 s
Diameter .....	15 mm
Length .....	115 mm
Measuring range temperature.....	-40 to +400 °C
Connection.....	Mini TE plug
Sensor type.....	K TYPE
Accuracy temperature.....	± 2.5 °C
Product Type.....	Surface probe