

P/N: T128775ACC

Copyright

© 2015, FLIR Systems, Inc.

All rights reserved worldwide. Names and marks appearing herein are either registered trademarks or trademarks of FLIR Systems and/or its subsidiaries. All other trademarks, trade names or company names referenced herein are used for identification only and are the property of their respective owners.

Document identity

Publ. No.: T128775ACC

Release:

Commit: 27816

Language: en-US

Modified: 2015-08-03

Formatted: 2015-10-17

Disclaimer



Specifications subject to change without further notice. Camera models and accessories subject to regional market considerations. License procedures may apply. Products described herein may be subject to US Export Regulations. Please refer to exportquestions@flir.com with any questions.



General description	
Rear mounting plate kit for mounting a FLIR AX8 camera.	
Physical data	
Shipping information	
Packaging, type	Cardboard box
List of contents	<ul style="list-style-type: none"> Rear mounting plate Screws
Packaging, weight	0.097 kg (0.21 lb.)
Packaging, size	170 × 64 × 75 mm (6.7 × 2.5 × 3.0 in.)
EAN-13	4743254002142
UPC-12	845188011666
Country of origin	Sweden

Compatible with the following products

- 71201-0101; FLIR AX8 9 Hz

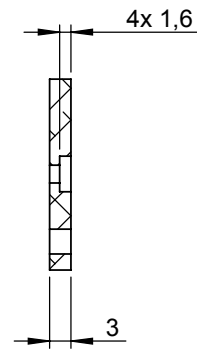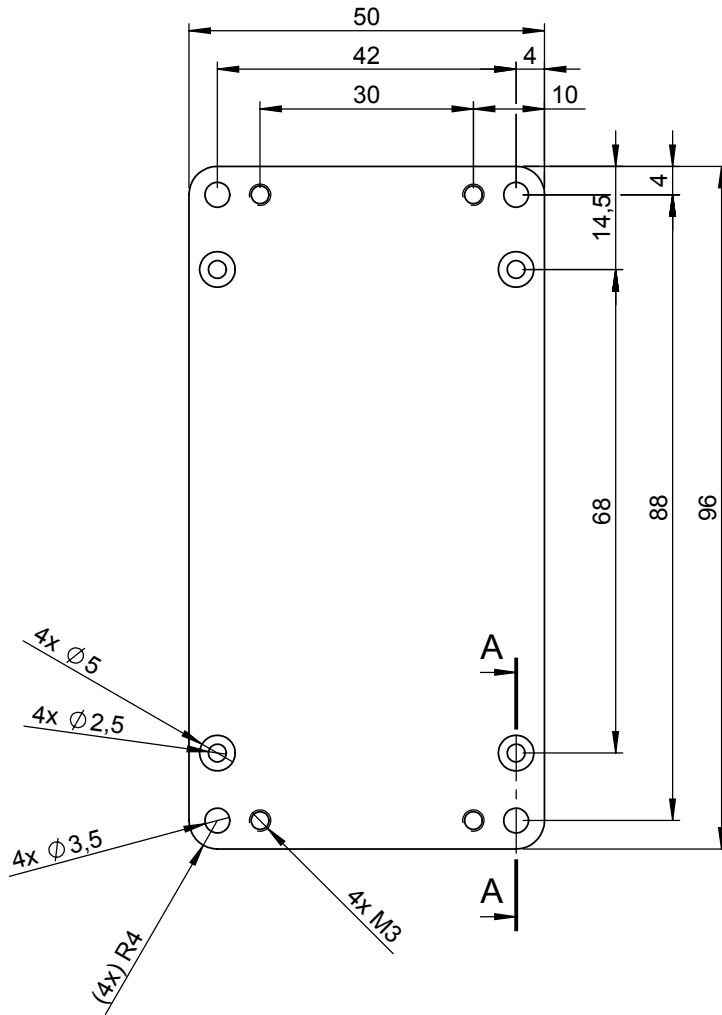

SECTION A-A

Konstr/Drawn J. MÄKINEN	Datum/Date 2015-03-06	Kontr/Check HAOS	Material EN AW-5052 or EN AW-5754			
Ändrad av/Modified by J. MÄKINEN	Ändrad/Modified 2015-05-21	Ytjämnhet/Roughness Ra µm	Ytbehandling/Surface treatment			
Där ej annat anges/Unless otherwise stated Gen tol ISO 2768-mK Utdrag ur/Excerpt from ISO 2768-m	Benämning/Denomination Plate mounting rear			Skala/Scale 1:1		Blad/Sheet 1(1)
0,5-6 ±0,1 Hålkårsradier (6)-30 ±0,2 Fillet radii (30)-120 ±0,3				Art.No.	Size A4	
				Ritn nr/Drawing No	Rev	