

# Datasheet

Item no. 1408768/ 1408769

V1\_0717\_01\_en

 

2 x USB 3.0 Panel Jack, Ø25mm

Front: 2 x Female Type A

Back: 2 x Female Type A

Item no.: 1408768- Silver

1408769- Black

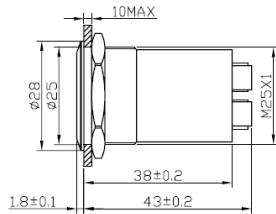

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification .....	Front: 2 x USB 3.0 Female Type A Back: 2 x USB 3.0 Female Type A
Mounting diameter .....	25 mm
Panel Thickness.....	1~10 mm
Operating Temperature.....	-25°C ~ +55°C (NO-Freezing)
Operating Humidity.....	45~85%RH(NO Condensation)
Body Material.....	Aluminium anodized (Silver color)
Transmission Rate .....	≥30MB/s

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.