

DATASHEET



2 x USB 3.0 Panel Jack, Ø25mm

Front: 2 x Female Type A

Back: 2 x Female Type A

Version08/16

Item no.: 1408768- Silver
1408769- Black

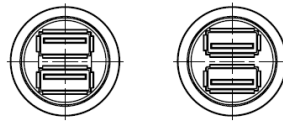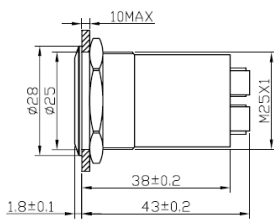

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification	Front: 2 x USB 3.0 Female Type A Back: 2 x USB 3.0 Female Type A
Mounting diameter	25 mm
Panel Thickness.....	1~10 mm
Operating Temperature.....	-25°C ~ +55°C (NO-Freezing)
Operating Humidity.....	45~85%RH(NO Condensation)
Body Material.....	Aluminium anodized (Silver color)
Transmission Rate	≥30MB/s