

# Datasheet

Item no. 1408770/ 1408771


V1\_0717\_01\_en

## RJ45 CAT5 8/8 Panel Jack

Front: Female

Back: Male with 60cm cable,  $\Phi$  22mm

Item no.: 1408770 – Silver  
1408771 – Black

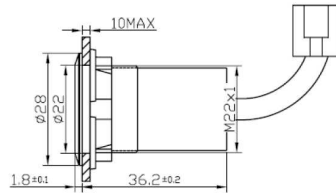

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.



Specification .....	Front: RJ45 Female Back: RJ45 Male with 60cm cable
Cable Standard.....	T568B
Mounting diameter.....	22 mm
Panel Thickness.....	1~10 mm
Body Material.....	Aluminium anodized (Silver color)
Transmission Rate .....	$\geq 30$ MB/s
Operating Temperature.....	-25°C ~ +55°C (NO-Freezing)
Operating Humidity.....	45~85%RH(NO Condensation)

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.