

 

0 504 62






LE05276AA
© Legrand 2006
Made in China

legrand®

Pro & Consumer Service
BP 30076 / F - 87002 Limoges Cedex 1
www.legrand.com

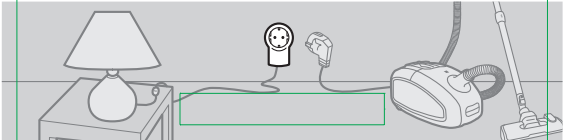

16 A - 230 V~
3680 W max.

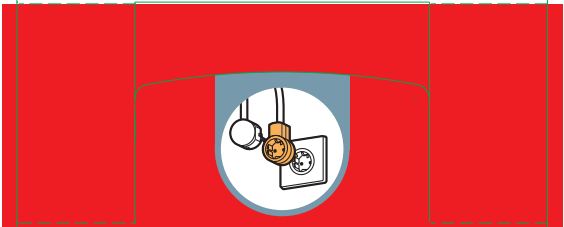 
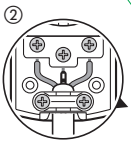


Special plugs with sockets

German standard



Pack	Cat.Nos	
8	6 946 70	2P+E + 2 x RJ 45 socket with voltage surge protector Protection of electrical and electronic devices and the telephone circuit against lightning and overvoltages With indicator showing the status of the voltage surge protector ADSL compatible RJ 45/RJ 11 I/O: Uc: 200 V, Uoc: 2 kV and Up: 600 V Supplied with 1.5 m RJ 11 cord
8	6 946 71	2P+E + 2 x USB socket + telephone support with voltage surge protector Protection of electrical and electronic devices against lightning and overvoltages With indicator showing the status of the voltage surge protector 5 V/1000 mA USB charger sockets for charging tablets, MP3 or MP4 players, mobile phones, etc. Telephone support with non-slip coating Supplied with 1 m retractable cable with micro-USB plug
8	0 504 62	Plug with 2P+E 16 A socket - 250 V~ Wires onto a cord connected to a device, enabling a second device to be connected to the same socket Plug 16 A/250V - 3680 W To be connected to a flexible cord 3G 1.5 mm ²
8	0 504 09	Plug with switch, 16 A - 250 V~ For fitting on a class I domestic appliance Equipped with an on/off switch Well adapted for appliance or multioutlet extensions non-equipped with an on/off button Plug 16A / 250V – 3680W To be connected to a 3G 1.5mm ² flexible cord

 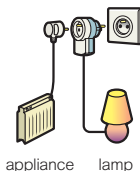

Spotlights, dimmable night lamps and night light



Pack	Cat.Nos	
12 12	0 506 78 0 506 79	Spotlights with battery Equipped with 2 high luminosity LED lamps (warm light/ cold light) Light intensity can be adjusted by keeping the lens pressed, if used as spotlight Can be removed and used as a torch in case of emergency Battery life: minimum 1.5 hours Turn on automatically to maximum intensity of cold light in case of black-out ○ White ● Black
12 12	0 506 76 0 506 77	Dimmable night lamps High luminosity LED spotlights to be used in either auto mode (day/night automatic sensor) or manual mode (on/off switching) Light intensity can be adjusted by keeping the lens pressed ○ White ● Black
8	0 506 73	Night light with LED with light-sensitive sensor, 230 V Automatic lighting thanks to sensitive sensor (day/night) LED spotlight technology Supplied with 4 solid-coloured labels and 1 customisable paper label

Operation of socket with telephone support Cat.No 6 946 71



See the video on spotlights benefits



See the video on dimmable night lamp benefits

