

THERMIX BASIC

Reference: KIT-THER-BASIC

- KIT-THER-BASIC-YB (yellow - white)
- KIT-THER-BASIC-YN (yellow - black)
- KIT-THER-BASIC-AB (blue - white)
- KIT-THER-BASIC-AN (blue - black)
- KIT-THER-BASIC-NB (black - white)
- KIT-THER-BASIC-NN (black)
- KIT-THER-BASIC-RB (red - white)
- KIT-THER-BASIC-RN (red - black)

Applications:

- Charges phones, tablets, cameras, power banks, and rechargeable batteries.
- Capable of supplying power up to 10 LED bulbs.
- Supplies power to USB and 12V devices.
- Propagation of hot air.




Technical specifications:

Weight:	1.350gr
Dimensions:	Length: 316mm. Height: 97mm. Width 137mm.
Maximum power:	18 W
Maximum voltage:	18 V
Power delivery at standard operating range:	9 W
Autonomy:	50.000 h. of continuous use
Operation temperature:	150 °C - 400 °C
Average consumption:	50gr. of gas or kerosene/h

Kit contents:

- Thermix.
- 12V / USB Converter.
- 2 PowerSpot "Water" 9W 5V bulbs.
- 12V double connector.
- 2 connectors-extenders for E27 bulbs.
- Operating instructions.

Available colours:

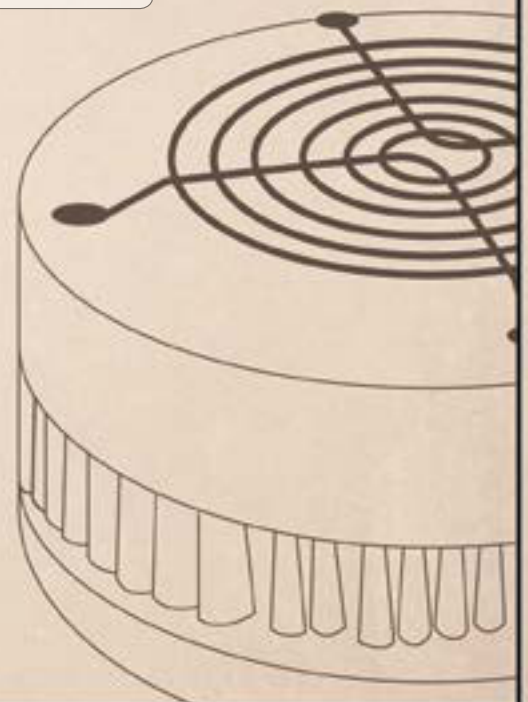

KIT-THERMIX BASIC

