







VOLTcraft®

Alligator clip set, different type, 42pcs/set

Item no.: 1417395

Version: 12/15



No.	Model no.	PCS	Delivery content	Photo	Specification
1	1-4	8	4 pcs red + 4 pcs black	<p>1-4 Alligator clip color:black,red L:35mm</p> 	Length: 35mm , 4A
2	1-1	10	5 pcs red + 5 pcs black	<p>1-1 Alligator clip (W/boot) color:black,red L1:27mm(small size) L2:31.5mm(large size)</p> 	Length: 27mm , 2A
3	1-2	8	4 pcs red + 4 pcs black	<p>1-2 Alligator clip (W/boot) color:black,red L1:35mm(small size) L2:40mm(large size)</p> 	Length: 35mm , 3A
4	1-3	4	2 pcs red + 2 pcs black	<p>1-3 Alligator clip (W/boot) color:black,red L:44mm(large size)</p> 	Length: 44mm , 5A




VOLT CRAFT®

Alligator clip set, different type, 42pcs/set

Item no.: 1417395


Version: 12/15

5/6

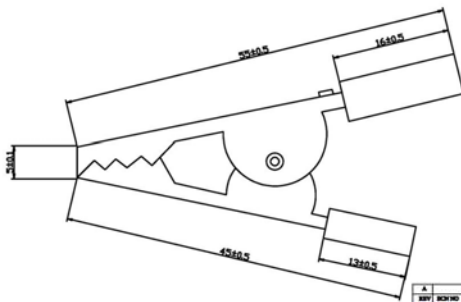


A	REV	NO	DATE	DESCRIPTION
				常州特锐电子技术有限公司 Changzhou Trafid Electronic Co., Ltd
DESCRIPTION				
GENERAL TOLERANCE		UNITS	DRAWING	
X ±0.20		mm	CHECKED	
Y ±0.20		mm	DRAWING	
Z ±0.20		mm	APPROVED	
TITLED ANGLE PROJECT				
SCALE		SHEET	UNIT	REV
NONE		1/1	MM	A

7

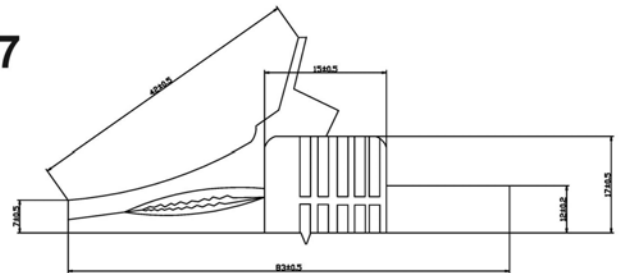


A	REV	NO	DATE	DESCRIPTION
				常州特锐电子技术有限公司 Changzhou Trafid Electronic Co., Ltd
DESCRIPTION				
GENERAL TOLERANCE		UNITS	DRAWING	
X ±0.20		mm	CHECKED	
Y ±0.20		mm	DRAWING	
Z ±0.20		mm	APPROVED	
TITLED ANGLE PROJECT				
SCALE		SHEET	UNIT	REV
NONE		1/1	MM	A

8

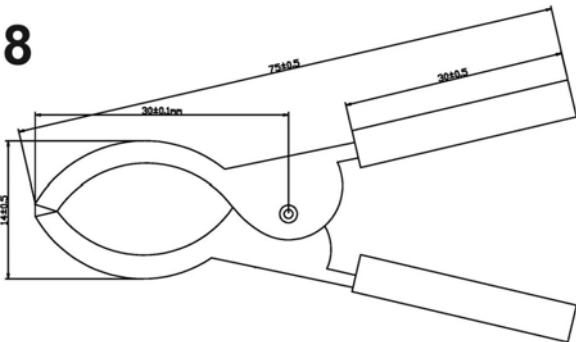

A	REV	NO	DATE	DESCRIPTION
				常州特锐电子技术有限公司 Changzhou Trafid Electronic Co., Ltd
DESCRIPTION				
GENERAL TOLERANCE		UNITS	DRAWING	
X ±0.20		mm	CHECKED	
Y ±0.20		mm	DRAWING	
Z ±0.20		mm	APPROVED	
TITLED ANGLE PROJECT				
SCALE		SHEET	UNIT	REV
NONE		1/1	MM	A

9

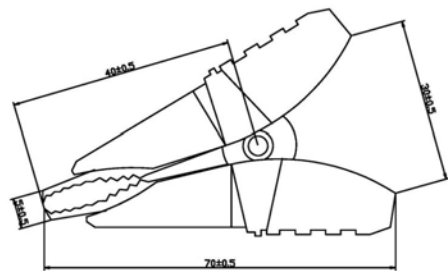

A	REV	NO	DATE	DESCRIPTION
				常州特锐电子技术有限公司 Changzhou Trafid Electronic Co., Ltd
DESCRIPTION				
GENERAL TOLERANCE		UNITS	DRAWING	
X ±0.20		mm	CHECKED	
Y ±0.20		mm	DRAWING	
Z ±0.20		mm	APPROVED	
TITLED ANGLE PROJECT				
SCALE		SHEET	UNIT	REV
NONE		1/1	MM	A



Alligator clip set, different type, 42pcs/set

Item no.: 1417395

Version: 12/15

Material.....	Steel
Insulation material.....	PVC
Soldering method.....	heating
Plated material.....	Nickel
Parts.....	Total 42pcs Alligator clips inside
Packaging.....	Transparent box
Box size.....	22x16.8x5.7cm
Rated voltage.....	< 50V AC/75V DC
Operating temperature.....	-20 to +70 °C
Storage temperature range.....	-20 to +70 °C
Operating humidity range.....	35%~95%
Storage humidity range.....	35%~95%