

# Datasheet

Item no. 1417396/ 1417397

V1\_0717\_01\_en


## RJ45 CAT5 8/8 Panel Jack, $\Phi 22$ mm

**Front: Female**

**Back: Female**

**BN no.: 1417396 – Silver**

**1417397 - Black**

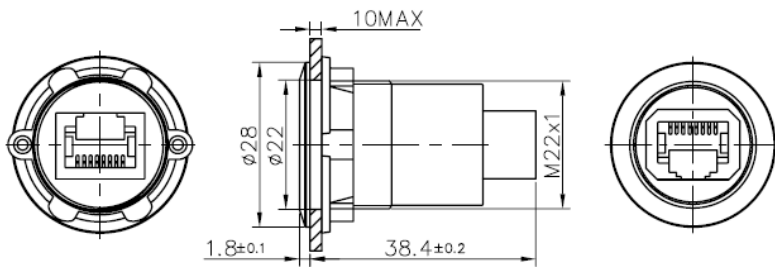

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Mounting diameter .....	22 mm
Body material .....	aluminium anodized(silver colour)
Operating and storage temperature .....	-20 to +55 °C
Operating and storage humidity .....	45 to 85 % RH
Panel thickness .....	1 ~ 10 mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau ([www.conrad.com](http://www.conrad.com)).  
 All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.