

RJ45 CAT5 8/8 Panel Jack, $\Phi 22$ mm


Version 12/15

Front: Female

Back: Female

BN no.: 1417396 – Silver

1417397 - Black

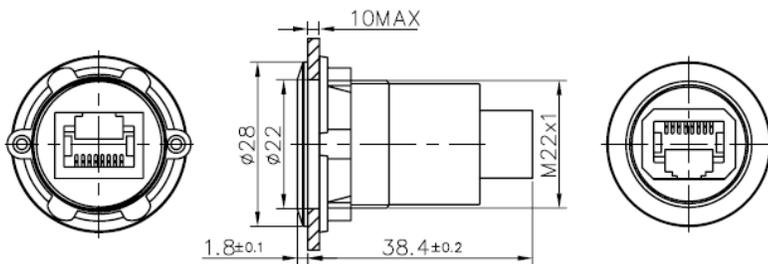

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification	RJ45
Mounting diameter	22 mm
Body material	aluminium anodized(silver colour)
Operating and storage temperature	-20 to +55 °C
Operating and storage humidity	45 to 85 % RH
Panel thickness	1 ~ 10 mm