


Cell Type N-600AAK


Specifications

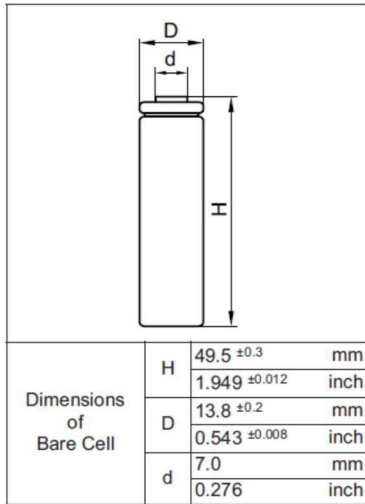


Nominal Capacity			600mAh				
Nominal Voltage			1.2V				
Charging Current		Standard	60mA				
		Quick	180mA				
Charging Time		Standard	14 to 16Hrs.				
		Quick	4 to 6Hrs.				
Ambient Temperature	Charge	Standard	0°C to +70°C [+32°F to 158°F]				
		Quick	10°C to +70°C [+50°F to 158°F]				
	Discharge		-20°C to +70°C [-4°F to 158°F]				
	Storage		-30°C to +70°C [-22°F to 158°F]				
Internal Impedance (Av.) (at 50% discharge)			12.0mΩ (at 1000Hz)				
Weight			22g/0.78oz				
Dimensions(D)×(H) (with tube)			14.3	⁰ _{-0.5}	× 50.2	⁰ _{-1.0}	mm
			0.56	⁰ _{-0.02}	× 1.98	⁰ _{-0.04}	inch

Typical Characteristics


Charge

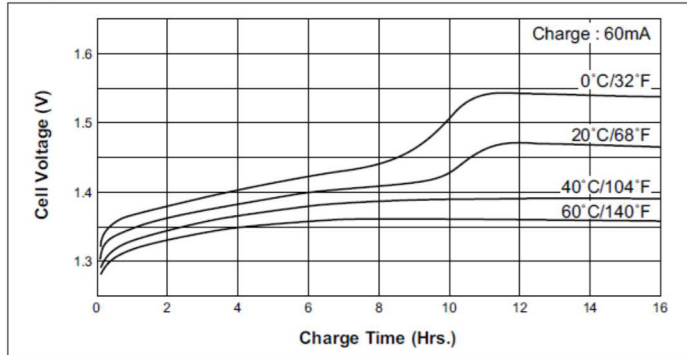


Discharge (at high rate)

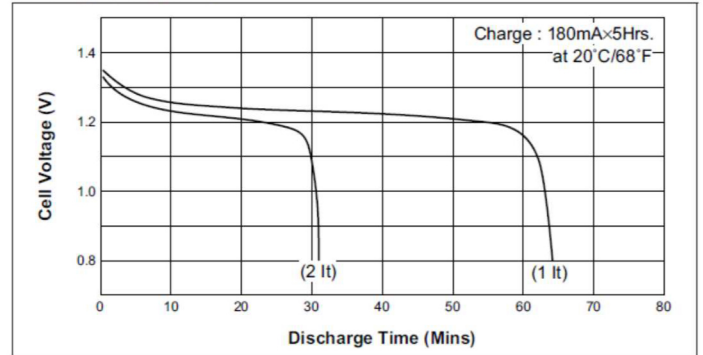


Charge

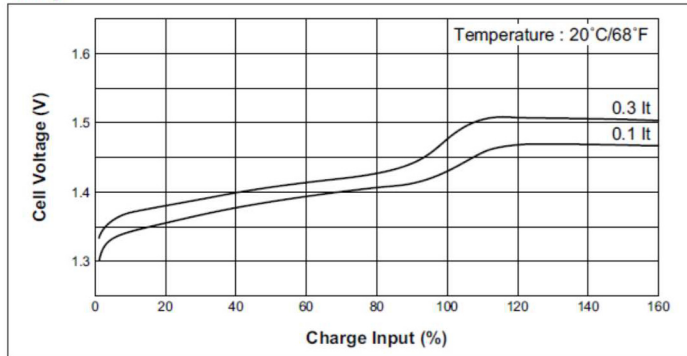

Discharge (at high rate)

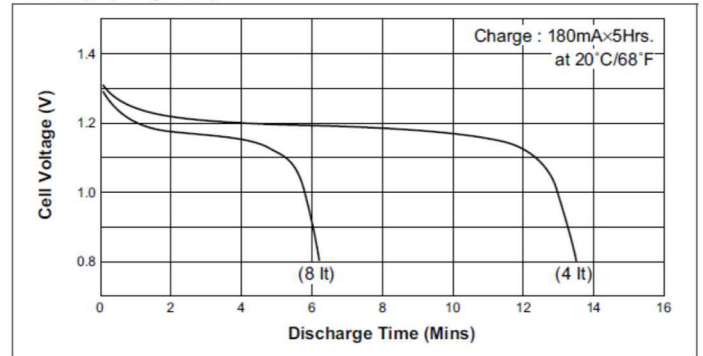

Discharge (at low rate)

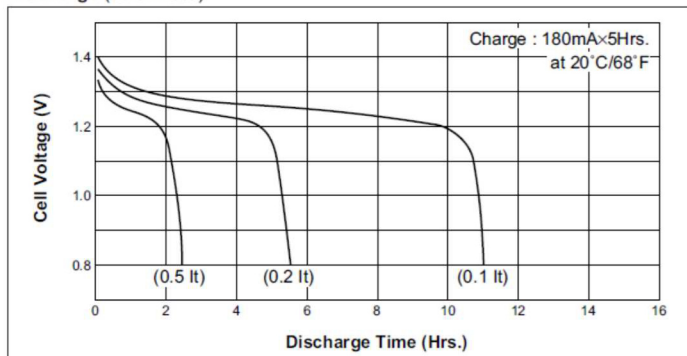

Temperature (Charge & Discharge)

