


Cell Type NC-2500SCR


Specifications

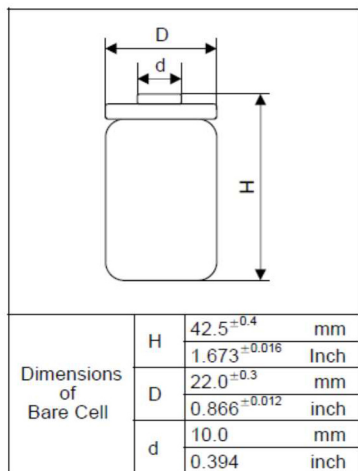


Nominal Capacity		2500mAh	
Nominal Voltage		1.2V	
Charging Current		Standard	250mA
		Fast	3750mA
Charging Time		Standard	14 to 16Hrs.
		Fast	about 1Hr
Ambient Temperature	Charge	Standard	0 °C to +45 °C [+32 °F to 113 °F]
		Fast	5 °C to +40 °C [+41 °F to 104 °F]
	Discharge		-20 °C to +60 °C [-4 °F to 140 °F]
	Storage		-30 °C to +50 °C [-22 °F to 122 °F]
Internal Impedance (Av.) (at 50% discharge)			4.5mΩ (at 1000Hz)
Weight (with tube)			Approx. 55g / 1.94oz
Dimensions(D)×(H) (with tube)			22.9 ⁰ _{-1.0} × 43.5 ⁰ _{-1.2} mm
			0.90 ⁰ _{-0.04} × 1.71 ⁰ _{-0.05} inch

Typical Characteristics


Charge

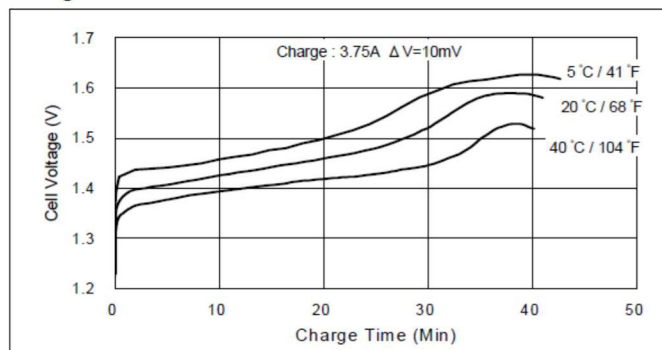


Discharge (at high rate)

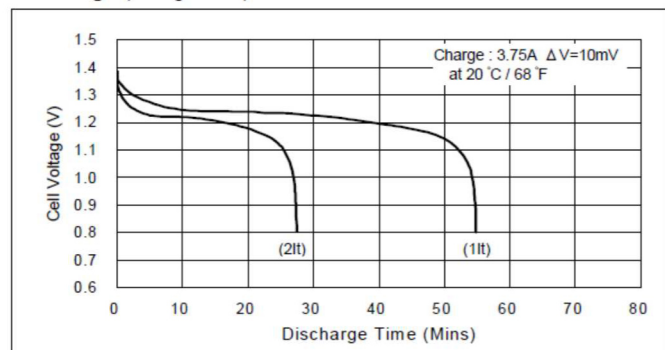


Cell Capacity (at various discharge rate)

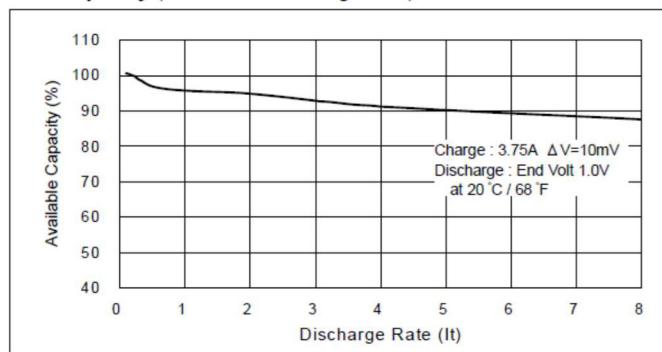

Discharge (at high rate)

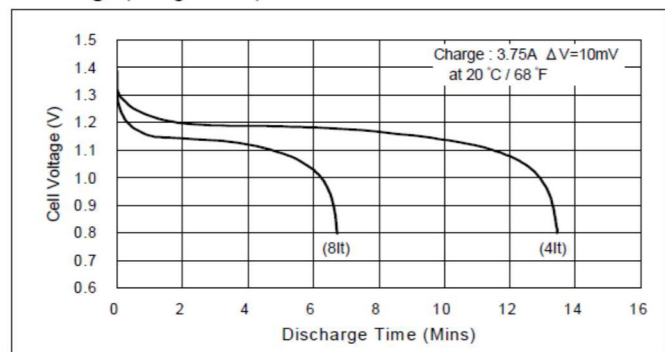

Discharge (at low rate)

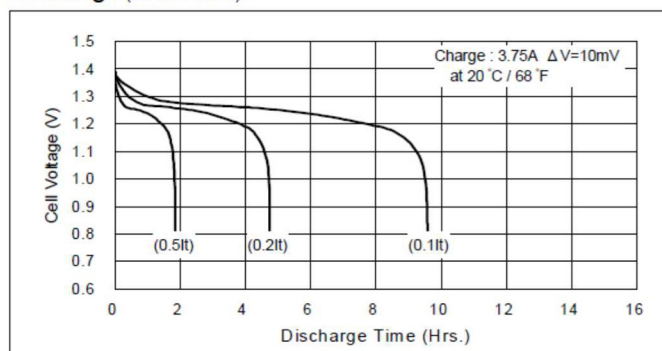

Temperature (Charge & Discharge)

