


Wireless Remote Control 2-channel for brand switch systems, flush-mount

Product ref.: 142237A0
PRODUCT FEATURES

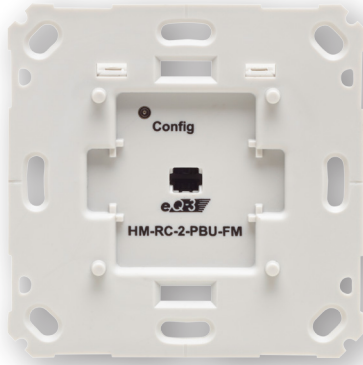

- Connected Homematic devices can be controlled via two channels per rocker switch
- 230 V mains operation - no batteries required
- Compact design for installation in size 60 flush-mounting box
- Easy to align with outer contour
- With the appropriate adapter, the device can be integrated into the most popular switch designs of leading manufacturers: Busch-Jaeger, Gira, Merten, Berker, Jung, düwi, Kopp
- Can also be integrated into existing installations in a cost-effective way by making use of existing frames and rockers
- Easy to assemble and install
- Multiple applications in connection with the CCU2

TECHNICAL SPECIFICATIONS

Supply voltage:	230 V/50 Hz
Current consumption:	9 mA (max.)
Power consumption in standby:	0.22 W
Degree of protection:	IP20
Ambient temperature:	5 to 35 °C
Installation:	only in normal commercial switch boxes (device boxes) in accordance with DIN 49073-1.
Dimensions (W x H x D):	71 x 71 x 37 mm (depth for flush-mounting: 32 mm)
Weight:	46 g
Radio frequency:	868.3 MHz
Typ. open area RF range:	200 m

LOGISTIC DATA

Product reference:	142237A0
EAN code:	4047976422371
Short description:	HM-RC-2-PBU-FM
Packing unit:	90
Packaging dimensions:	122 x 112 x 48 mm
Total weight:	119 g

PACKAGE CONTENTS

1x Wireless Remote Control
1x Operating manual in DE and EN