


1, Patchcord Length (m)

Length L	Tolerance T	Part No	Packing Bag Size
L = 2.0m	±0.10m	750837	180x280mm
L = 5.0m	±0.10m	750844	180x280mm
L = 10.0m	±0.10m	750851	180x280mm

2, Connector Test Specifications

Parameters	Specifications
Insertion Loss	≤0.30dB
Return Loss	≥35.0dB
Durability(1000Mating)	0.2dB Max.Increase
Operating Temperature	-40℃~75℃
Storage Temperature	-40℃~85℃

Cable Profile View

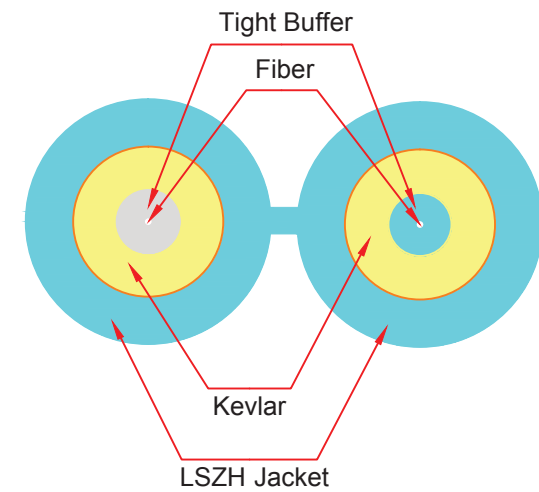

ITEM	DESCRIPTION	Q'TY
1	SC Dust Cap (Clear)	4
2	SC/UPC Connector MM Duplex 3.0mm (Beige)	2
3	SC Duplex Clip (Beige)	2
4	SC 3.0 Boot (Red)	2
5	SC 3.0 Boot (Black)	2
6	MM Duplex 50/125 OM3 3.0mm LSZH Cable(Aqua)	Xm



DRAWN BY	LW	SPEC.	SC/UPC-SC/UPC MM-Duplex 50/125 OM3 3.0mm Patchcord L=Xm, LSZH Aqua Jacket			A
CHECK BY	ZH	CUSTOMER		SHEET /P	SCALE NONE	UNIT: mm
APPD. BY	ZH	DWG. NO.		DATE 2015-04-07	VIEW	