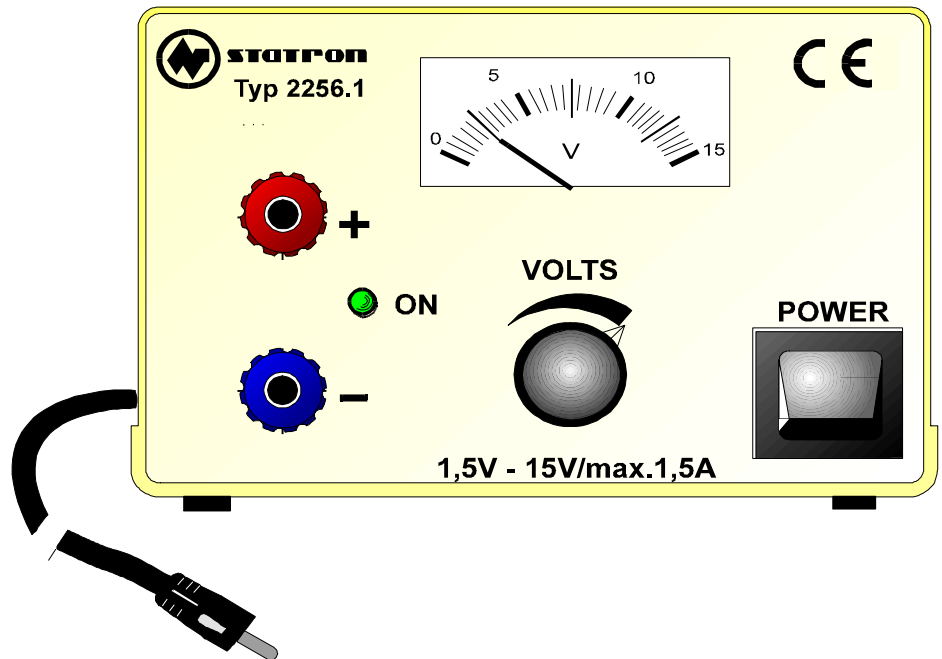


**STATRON**

Gerätetechnik GmbH

DC voltage regulator**rated power****22,5 W****equipment qualities**

- Linear automatic controller with triac before automatic controller
- short circuit proof machine
- output mass-free

**technical parameter**

specification	type	2256.1
DC output voltage		1,5V - 15V
DC output current		1,5A
CV stability net +6/-10%		25mV
CV stability load 0-100%		50mV
CV remaining ripple Ueff		10mV
correction time load 10-100%		100µs
adjuster Ua		Potentiometer 270°
characteristic		U/I
display voltage		analog display
output connector		4mm sockets
dimensions WxHxD in mm		110 x 80 x150 mm
operating temperature		0 - 35°C
max.relative humidity		85% bei 35°C
AC input voltage		230 V +6%/ -10% 50Hz
AC testing voltage		EN 61010 ; EN 61558-2-4
color		RAL 7035
weight		2,0 kg
safety class		I
electromagnetic compatibility		EN 61000-6-3 ; EN 61000-6-2

STATRON Gerätetechnik GmbH
 Ehrenfried-Jopp-Str.59
 15517 Fürstenwalde
 Tel.:+49 3361 372101
 Fax :+49 3361 372103
 e-Mail:statron@statron.de
 Internet:www.statron.de