

GB Data sheet

LVC-005 DC connection cable

Item no. 1434426

Features

- Output via alligator clips
- Max. current 2.5 A
- Length 18 cm
- For connection with an optional power adapter

Suitable for item number

- 510834
- 511434
- 512725
- 512726

Technical data

Cable length 18 cm

Cable Ø 3.6 mm (2 x 1.8 mm)

AWG 20AWG


Current..... max. 2.5 A

Output plug type 01E

Operating conditions..... 0 to +40 °C, 20 – 85 % RH (non-condensing)

Storage conditions..... -20 to +60 °C, 10 – 90 % RH (non-condensing)

Weight approx. 15 g

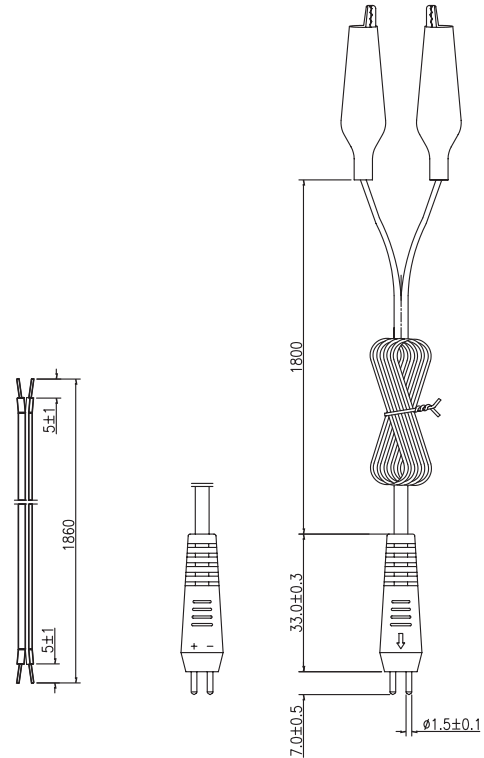

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represent the technical status at the time of printing.

Copyright 2022 by Conrad Electronic SE.

1434426_V2_1221_01_PIX_ds