

DIGITUS® Open Racks, unmounted



✓ 2.0 / 4.0 mm strong steel material

✓ Load capacity up to 600 kg

✓ Unmounted, flat-pack delivery

✓ Single frame or double frame

Abstract

DIGITUS® Open Racks, unmounted, single frame or double frame version, 530 mm width - 380, 870 and 1070 mm depth

Features

- 2.0 mm strong steel material on frame system
- 4.0 mm strong steel material on top and bottom L-support connection pieces
- Load capacity: 600 kg
- Modular structure which allows universal mounting options on each profile
- incl. adjustable feet group
- Delivery in unmounted flat-pack
- Available in 5 different height units from 27U up to 48U
- Single frame or double frame option
- Double frame version is equipped with brushed cable entry on top and bottom parts
- Standard color grey (RAL 7035) and black (RAL 9005)

Product Overview

The unmounted open racks from DIGITUS® Professional offer network- or server application possibilities where there is no need of a closed enclosure due to security, climatized and dust free environments like data centers, laboratories, clean rooms, etc. The open racks are delivered unmounted in a flat-pack which provides a cost effective and economical solution. While being able to install quick and easy it consists of strong material for maximum performance.

Product Images - Packaging

Single frame



Double frame



Product Number Information

Open Racks - Single Frame 380 mm depth

DN-19 27U-S	27U single frame open rack, unmounted, 1356x530x380 mm, grey (RAL 7035)
DN-19 27U-S-SW	27U single frame open rack, unmounted, 1356x530x380 mm, black (RAL 9005)
DN-19 36U-S	36U single frame open rack, unmounted, 1756x530x380 mm, grey (RAL 7035)
DN-19 36U-S-SW	36U single frame open rack, unmounted, 1756x530x380 mm, black (RAL 9005)
DN-19 42U-S	42U single frame open rack, unmounted, 2022x530x380 mm, grey (RAL 7035)
DN-19 42U-S-SW	42U single frame open rack, unmounted, 2022x530x380 mm, black (RAL 9005)
DN-19 45U-S	45U single frame open rack, unmounted, 2156x530x380 mm, grey (RAL 7035)
DN-19 45U-SW	45U single frame open rack, unmounted, 2156x530x380 mm, black (RAL 9005)
DN-19 48U-S	48U single frame open rack, unmounted, 2289x530x380 mm, grey (RAL 7035)
DN-19 48U-SW	48U single frame open rack, unmounted, 2289x530x380 mm, black (RAL 9005)

Open Racks - Double Frame 870 mm depth

DN-19 27U-D	27U double frame open rack, unmounted, 1356x530x870 mm, grey (RAL 7035)
DN-19 27U-D-SW	27U double frame open rack, unmounted, 1356x530x870 mm, black (RAL 9005)
DN-19 36U-D	36U double frame open rack, unmounted, 1756x530x870 mm, grey (RAL 7035)
DN-19 36U-D-SW	36U double frame open rack, unmounted, 1756x530x870 mm, black (RAL 9005)
DN-19 42U-D	42U double frame open rack, unmounted, 2022x530x870 mm, grey (RAL 7035)
DN-19 42U-D-SW	42U double frame open rack, unmounted, 2022x530x870 mm, black (RAL 9005)

Open Racks - Double Frame 1070 mm depth


DN-19 42U-D-SRV	42U double frame open rack, unmounted, 2022x530x1070 mm, grey (RAL 7035)
DN-19 42U-D-SRV-SW	42U double frame open rack, unmounted, 2022x530x1070 mm, black (RAL 9005)
DN-19 45U-D-SRV	45U double frame open rack, unmounted, 2156x530x1070 mm, grey (RAL 7035)
DN-19 45U-D-SRV-SW	45U double frame open rack, unmounted, 2156x530x1070 mm, black (RAL 9005)
DN-19 48U-D-SRV	48U double frame open rack, unmounted, 2289x530x1070 mm, grey (RAL 7035)
DN-19 48U-D-SRV-SW	48U double frame open rack, unmounted, 2289x530x1070 mm, black (RAL 9005)

Logisitic Information


Height unit	Height in mm	Depth in mm	Packaging 1 dimensions (HxWxD) in mm	Packaging 2 dimensions (HxWxD) in mm	Net/Gross weight in kg
27U	1356 mm	380 mm	1375x165x120 mm	----	20.0 / 21.0
		870 mm	1375x165x150 mm	120x550x550 mm	34.2 / 35.2
36U	1756 mm	380 mm	1775x165x120 mm	----	22.5 / 23.5
		870 mm	1775x165x150 mm	120x550x550 mm	38.4 / 40.0
42U	2022 mm	380 mm	2040x165x120 mm	----	23.5 / 24.0
		870 mm	2040x165x150 mm	120x550x550 mm	41.0 / 43.0
		1070 mm	2040x165x150 mm	120x750x750 mm	42.8 / 45.0
45U	2156 mm	380 mm	2175x165x120 mm	----	24.1 / 25.6
		1070 mm	2175x165x150 mm	120x750x750 mm	44.1 / 46.3
48U	2289 mm	380 mm	2310x165x120 mm	----	24.7 / 26.2
		1070 mm	2310x165x150 mm	120x750x750 mm	45.2 / 47.8

Technical Drawings


Single Frame - 380 mm depth

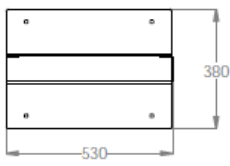


BOTTOM VIEW

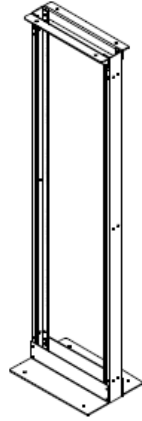


ISOMETRIC VIEW

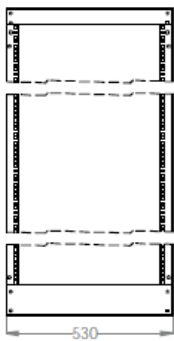


FRONT VIEW

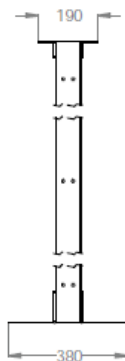


SIDE VIEW

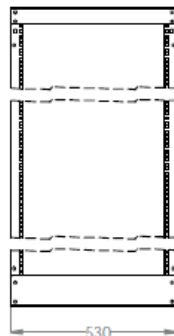


REAR VIEW

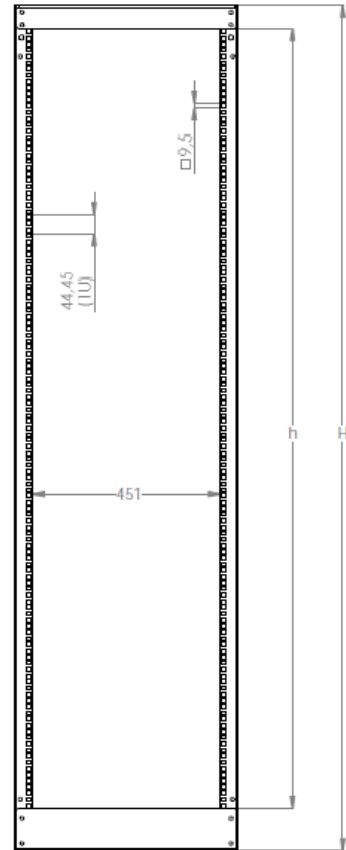


DIMENSIONS IN
WIDTH AND HEIGHT

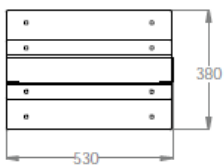

TOP VIEW

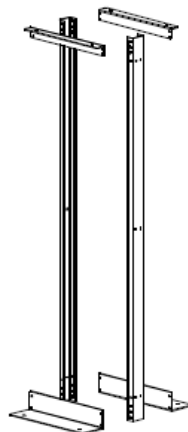


EXPLODED VIEW

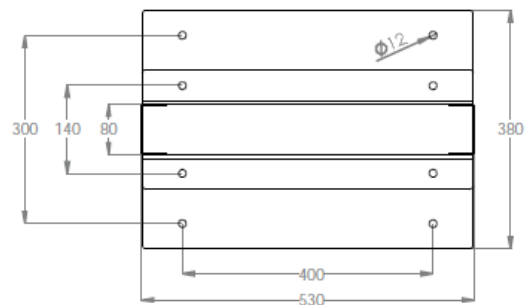


TOP VIEW
MOUNTING DIMENSIONS


Double Frame - 870 mm depth

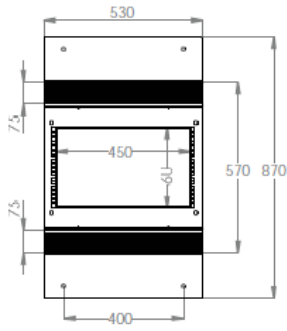


BOTTOM VIEW

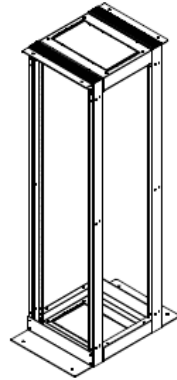


ISOMETRIC VIEW

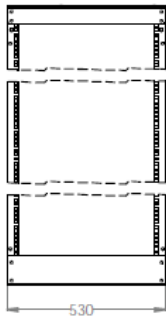


FRONT VIEW

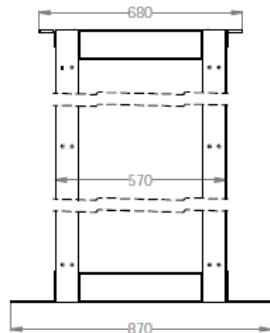


SIDE VIEW

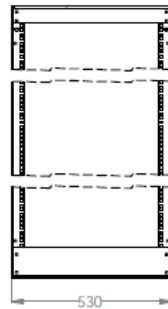


REAR VIEW

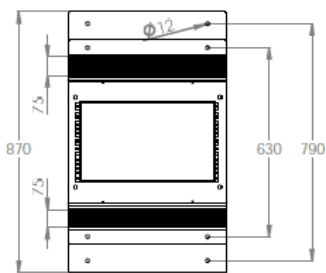

TOP VIEW

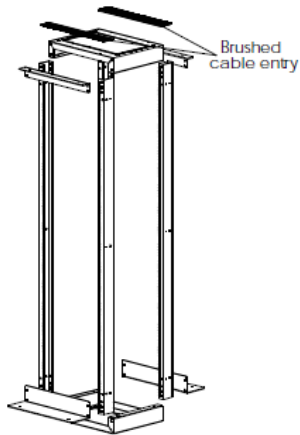

EXPLODED VIEW

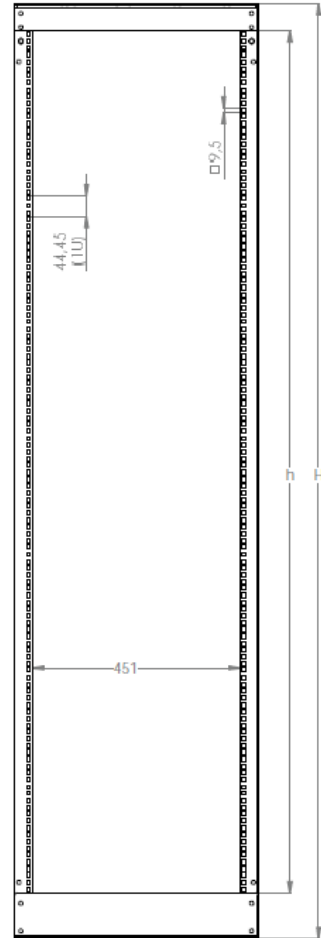

DIMENSIONS
IN
WIDTH AND HEIGHT

Double Frame - 1070 mm depth

