


DATASHEET

PVC Twin Cable, 2 x 0.75 mm² ,10 M, Grey

Version 07/16

Item no. 1484651

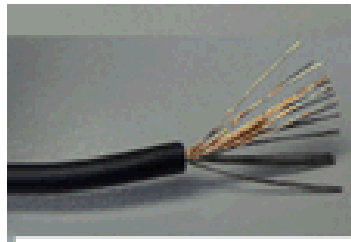

Operating temperature	-20 °C to 70 °C
Jacket, outer dimension.....	PVC 4.5 x 2.3 mm
AWG.....	19
No. of conductors.....	2 x 0.75 mm ²
CCA strand per conductor.....	27 x 0.19 mm
Color.....	Grey
Capacitance conductor.....	140 pF
Voltage.....	Less than 50 V/DC or 75 V/AC
Insulation resistance.....	Min 200 M Ω x km
Operating humidity.....	10 - 90 % RH
Packaging.....	10 meter spool