




 

 
Data sheet

Article Description

Rocker Switch Type 3634

12 A, 250 Vac, 2-pole, on/off-switch, T 125°,
snap-in mounting cut-out 19 x 13 mm
faston 4.8 x 0.8 mm,
rocker printing white 0-I,
with and without illumination,

Article Picture

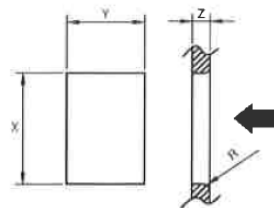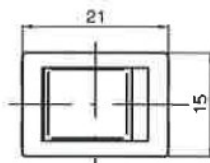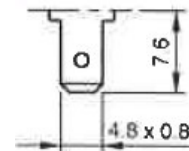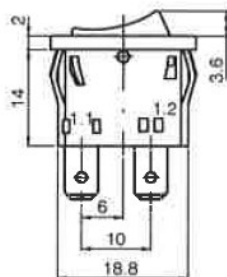

Z	Y	X
0,70 ... 1,25	13,0 ±0,1	19,1 ±0,1
1,25 ... 2,0	13,0 ±0,1	19,4 ±0,1
2,0 ... 3,0	13,0 ±0,1	19,7 ±0,1

<i>inter BÄR-No.</i>	<i>Colour housing/rocker</i>	<i>Version</i>
3634-201.22	black/black	without illumination
3634-250.22	black/green	with illumination

Technical modifications reserved!
Works at 230 V-mains must only be carried out by a specialist!