

# Model No.:HPE-103-24V

## 1.Scope

This specification is applied to Piezo Siren (Self-Drive Type)

The product describe below are used for buzzer in various alarm systems.

## 2.Basic Condition

2.1 Rated Voltage:24VDC

2.2 Operating Voltage:20~28VDC

2.3 Operating Temperature Range:-20 °C~+70 °C

2.4 Storage Temperature Range:-30°C~+85°C

## 3.Electrical Characteristics

3.1 Sound Press Level: $\geq 100$ dB at 100cm / 24VDC


3.2 Consumption Current: $\leq 100$ mA at 24VDC

3.3 Resonate Frequency:4400Hz $\pm$ 500Hz

3.4 Tone Nature: Siren Sound

3.5 Material: ABS

## 4.Measuring Method

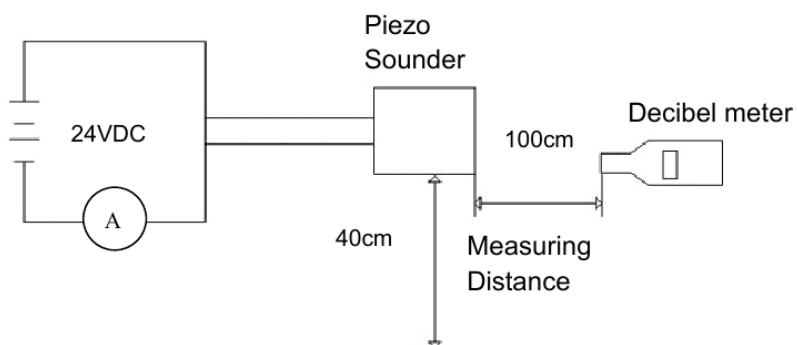

## 5.Sound Press Level & Consumption Current Curve

