



D-SC1500H Specifications

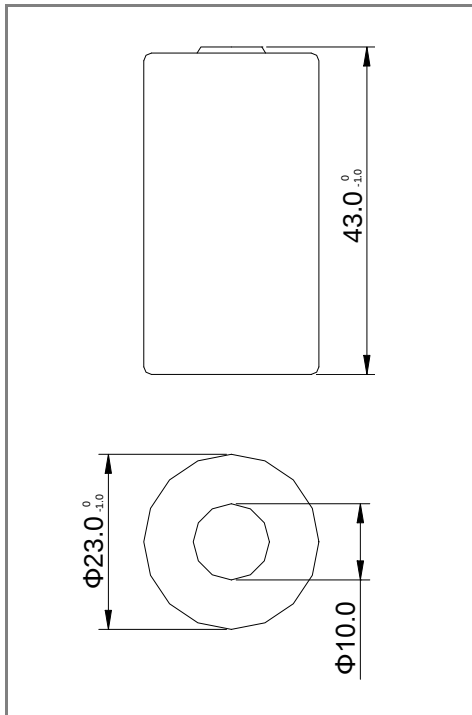


Nominal Capacity	1500mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	< 8mΩ
Charge	
Standard Charge (1C)	150mA x 15h
Trickle Charge (0.05C)	75mA x 1.2h
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	23.0mm
Height	43.0mm
Weight	49 g
Ambient Temperature	
Standard charge	0 ~ 60℃
Trickle charge	0 ~ 60℃
Discharge	-20 ~ 70℃
Storage	-20 ~ 45℃


Standard charge characteristics

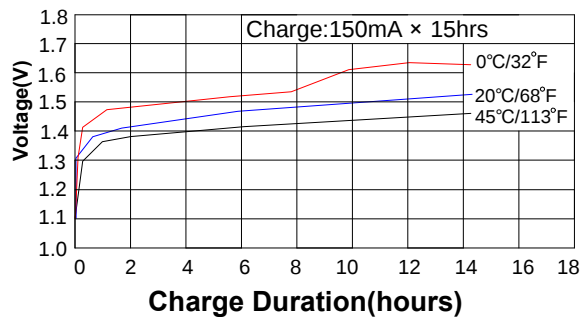

Trickle charge characteristics

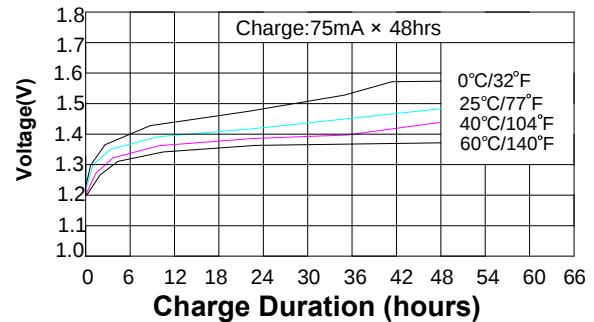

Discharge characteristics

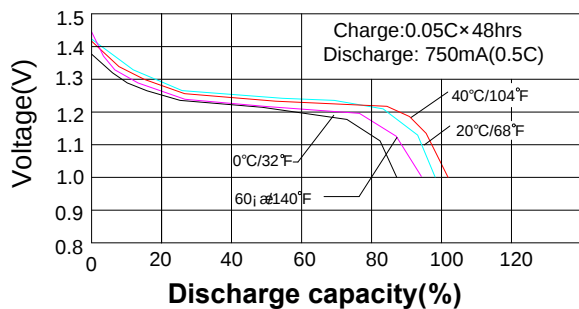

Charge efficiency

