



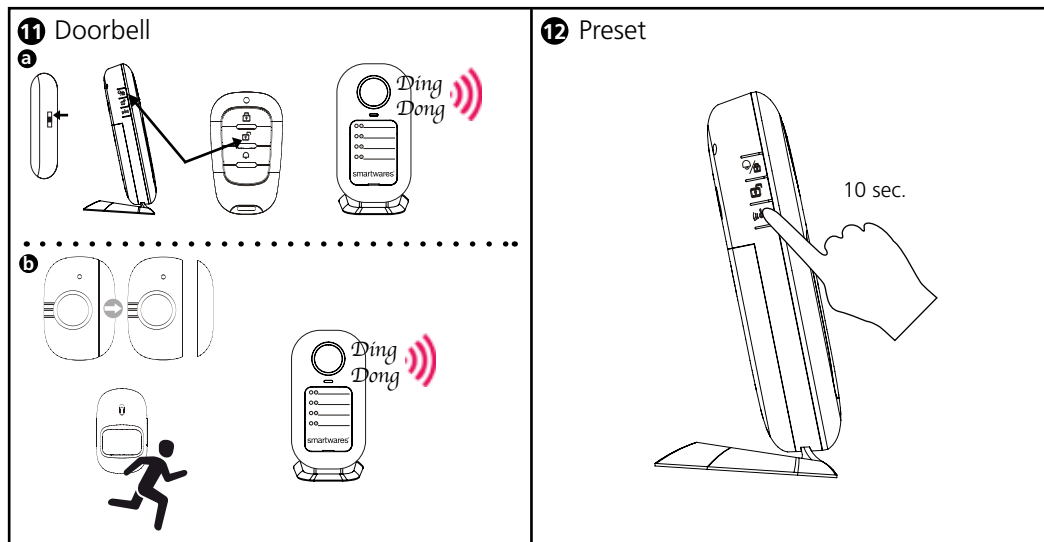


SPECIFICATIONS

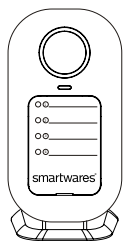

Transmission Frequency	433.92 MHz
Quantity	1
Ring time	30 seconds
Alarm sound intensity	110db (distance: 30cm)
Supply voltage	6V (1.5V x 4 pcs AA Alkaline batteries)
Power consumption	0.9W



Transmission Frequency	433.92 MHz
Transmission Distance	ca. 30m
Quantity	2x maximum
Supply voltage	3V (CR2032 Alkaline batteries)
Power consumption	0.03W
The total number coding	1000 000

 

Transmission Frequency	433.92 MHz
Transmission Distance	ca. 30m
Quantity	2x maximum
Ring time	10 seconds
Alarm sound intensity	90db (distance: 30cm)
Supply voltage	4.5V (1.5V x 3 pcs Ag13 Alkaline batteries)
Power consumption	0.45W
The total number coding	1000 000



Transmission Frequency	433.92 MHz
Transmission Distance	ca. 30m
Quantity	2x maximum
Sensing distance	0-10m
Sensing angle	110°
Alarm sound intensity	110db (distance: 30cm)
Supply voltage	3V (1.5V x 2 pcs AAA Alkaline batteries)
Power consumption	0.03W
The total number coding	1000 000

433,92 MHz
R&TTE
APPROVED



CUSTOMER SERVICE	
NL : 0900-2088888	Lokaal tarief
BE : 070-233031	(NL) Lokaal tarief
FR : 0800-97570	(FR) Gratuit
FR : 0825 560 650	15ct/min
DE : +49 (0) 1805 010762	14ct/Min, dt. Festnetz
UK : +44 (0) 345 230 1231	Mobil max. 42ct/Min
ES : +34 938427589	
www.smartwares.eu	



smartwares®

SC50/6 | 10.023.75









Mini alarm system

Wireless alarm system
4 detectors & 2 RF-remotes



EN Wireless alarm system
DE Funkalarmanlage
PL Osobis zostawisko system

NL Draadloos alarm systeem
FR Systeme d'alarme sans fil
ES Alarma inalambrico

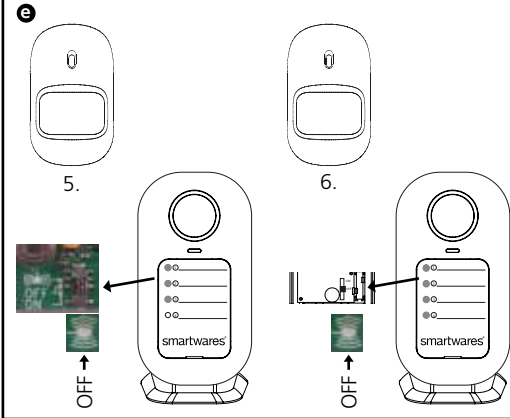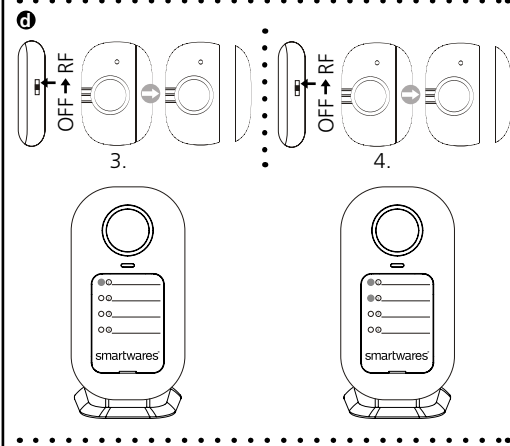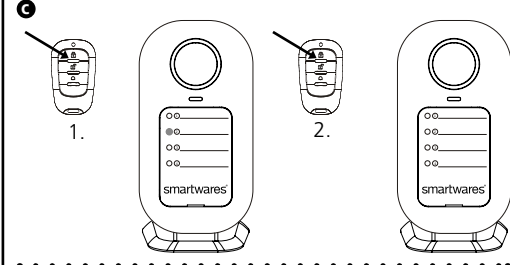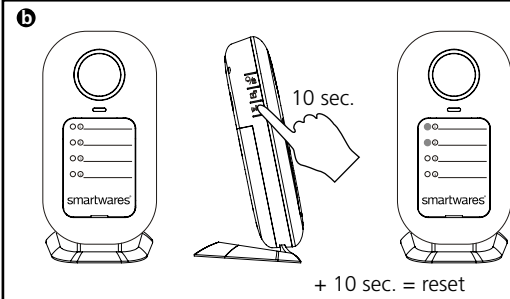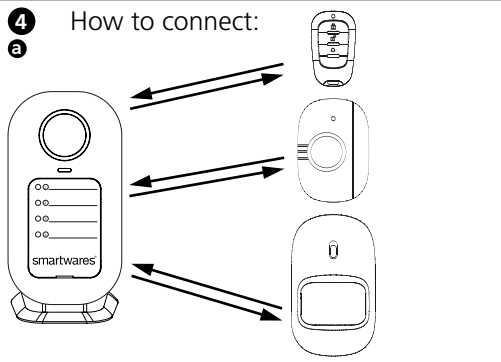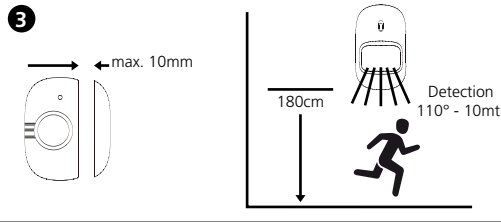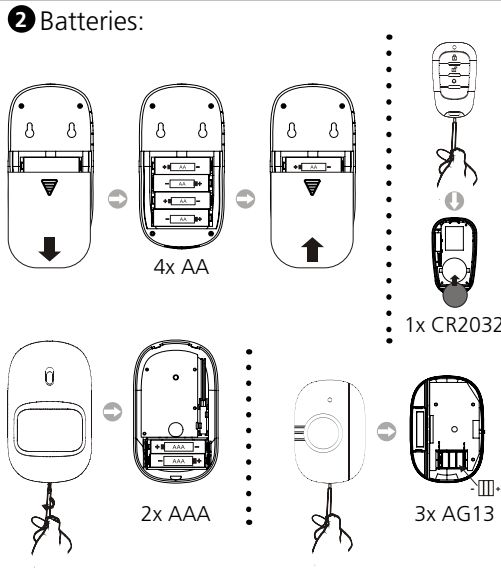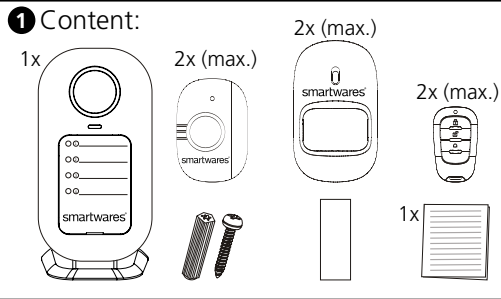

Learning = not required after buying
After RESET = Learning

