

**Female Header
Pitch 2.54 mm angled**

Double row, height 8.5 mm



SPECIFICATION:

Current rating: 3 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 1000 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: PBT UL94V-0
 Contacts: Copper alloy

FINISH:






Contacts: Gold Flash

HANDLING:

Processing: Wave soldering
 Packing: Tube

TOLERANCE:

.X ± 0.25
 .XX ± 0.20

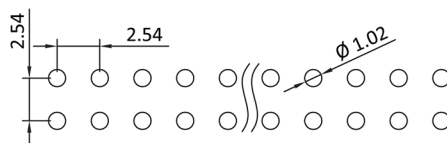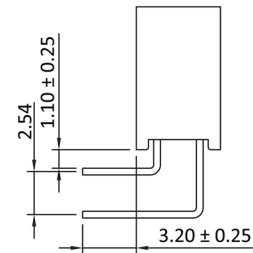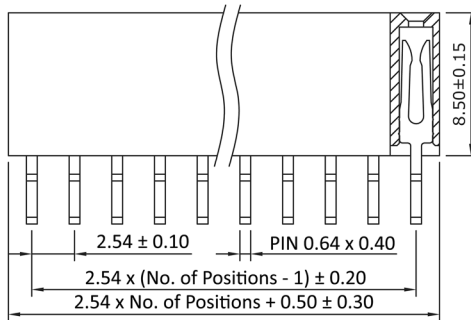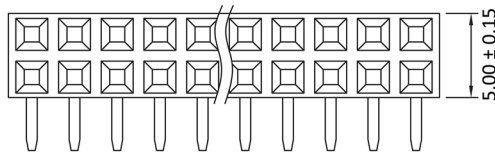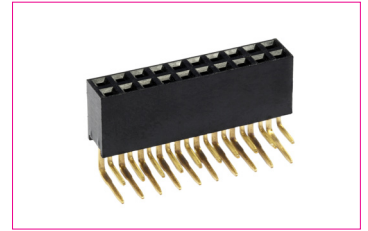

Recommended PCB Layout
(PCB TOLERANCE ± 0.05)

Order-Information

Identifier:	Version:	No. of contacts:
BL	W	#
Female Header Pitch 2.54 mm double row, height 8.5 mm	W: Angled	2X2: 2 x 2
		2X3: 2 x 3
		2X4: 2 x 4
		:
		2X40: 2 x 40